

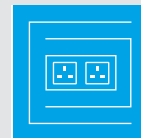


BR Dado Systems

Cable Management Products

- BR - uPVC
- BRH - Halogen Free Plastic
- BRA - Aluminium
- BRS - Steel

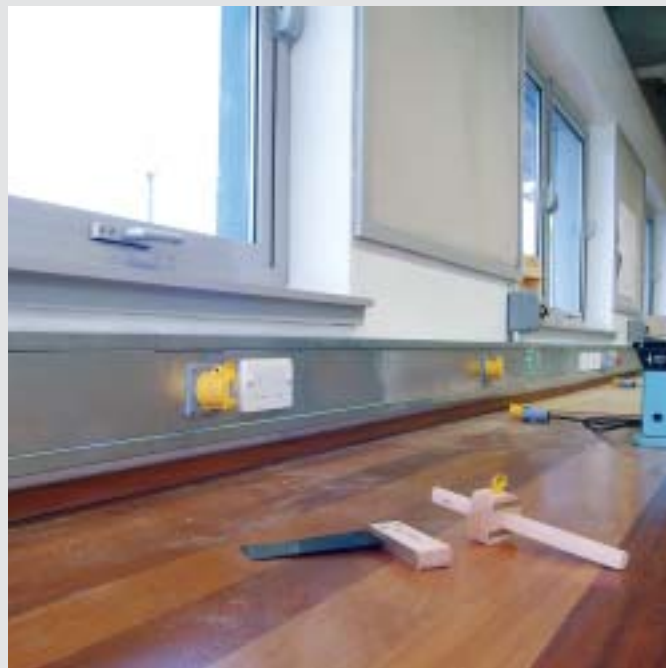

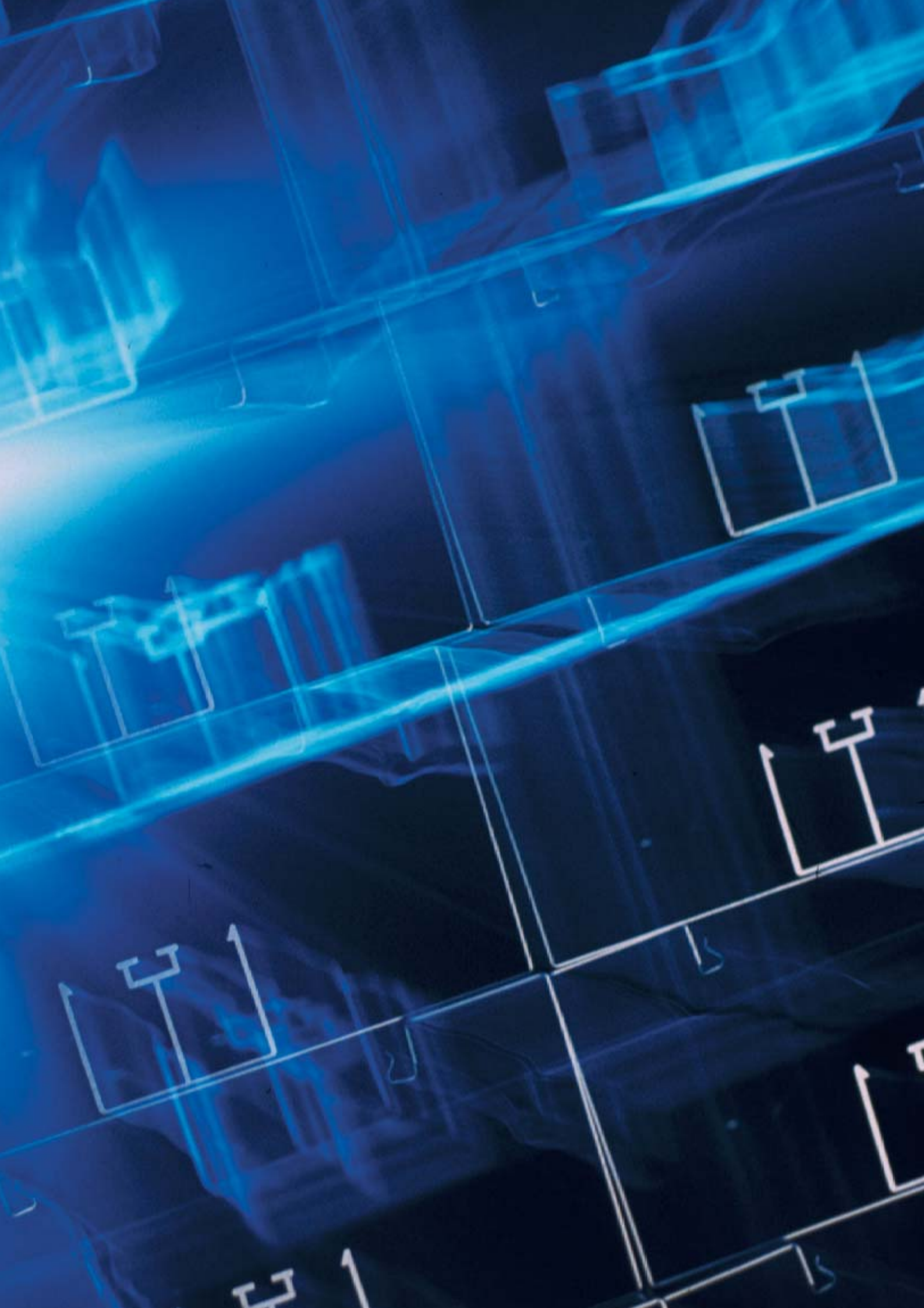

Tehalit is part of the Hager group. And that's important to you. It means you'll enjoy the benefits of massive on-going investment in better manufacturing resources, research and development and customer service plus a cross-fertilisation of skills and technologies between the member companies. Hager itself was founded in 1955. It began as a family business and is still independently owned, even though, today, it is one of the world's leading manufacturers and suppliers of electrical control and distribution systems.

In addition to Tehalit cable management systems the group includes Hager, Klik and Ashley.



Customer service centre for national sales enquiries.

Technical engineers offer both national and local support.

Help is just a call or click away

Sales Hotline

For all your sales enquiries.
e-mail:

0870 240 2400
sales@hager.co.uk

Technical Helpline

For all your technical enquiries.
e-mail:

0870 607 6677
technical@hager.co.uk

Hager Online

www.hager.co.uk

For general information on Hager brands.
e-mail:

info@hager.co.uk

hager

ashley

klik

TEHALIT



Hager offer a comprehensive range of electrical distribution equipment up to 1600 Amps



Ashley, whose wiring accessories are synonymous with quality and reliability.



Klik has transformed the speed and efficiency of electrical connections.



Tehalit products provide the answers for every cable management situation.

BR Dado Systems

When a perimeter system requires a combination of sophistication and strength the BR range offers everything you need.

Available in four materials to give you the choice and flexibility for your installation requirements.

BR uPVC

A classically designed PVC trunking. Easy to work with, PVC offers a lower cost installation.

BRH Halogen free plastic

Halogen free offers peace of mind for public buildings, where low flammability and minimal release of toxic gases in the event of fire is essential.

BRA Aluminium

For the ultimate in prestigious installations, aluminium offers elegant design combined with practical functionality.

BRS Steel

Steel has a timeless elegance of its own and will stand up to considerable mechanical stress.

Available in a galvanised finish this trunking is ideal for use when the building services are visible.



The tehalit BR system can be used to hide radiators, pipework or unsightly posts. The use of the fins and grills can ease installation and minimise the need for countless corners or additional fabrication on site.






 



 



 

 

 

 

 

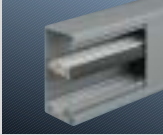

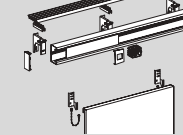
The BR family is a multi-compartment trunking system, capable of providing an efficient cable management solution for both new build and refurbishment projects.

Ideally suited for installations that require large numbers of cables to be carried in an unobtrusive, safe and elegant way.

A range of colour and finish options are available. We have a dedicated Specials Team who can facilitate bespoke lengths or non-standard profiles. Please contact us for further information.



Product range overview

Select material type	Trunking size	130mm	170mm	210mm
 <p>BR uPVC A classically designed PVC trunking. Easy to work with, PVC offers a lower cost installation.</p>		 130 x 68  130 x 83	 170 x 68  170 x 85	
 <p>Halogen free plastic Offering peace of mind for public buildings.</p>		 130 x 68	 170 x 68	
 <p>BRA Aluminium Up-market styling that will blend perfectly with interior decor of the highest order.</p>		 130 x 68  130 x 83	 170 x 68  170 x 83	 210 x 68
 <p>BRS Steel Steel will stand up to considerable mechanical stress and BRS is available in many RAL colours.</p>		 130 x 66  130 x 83	 170 x 66  170 x 83	 210 x 66  210 x 83
<p>Common Accessories Dividers. Outlet boxes. Earthing components. Locking system. Brackets and Fins. Installation instructions Alphanumerical listing page 28.</p> <p>Note: All dimensions in mm.</p>				

Ordering Information

Trunking Part Numbers

BR 70130 / 1 / 9010


BR refers to the range.
70130 refers to the dimensions.
1 base.
9010 refers to RAL No.

Ranges


BR = uPVC.
BRH = Halogen Free Plastic.
BRA = Aluminium.
BRS = Steel.

Descriptions


1 = base.
2 = Lid.

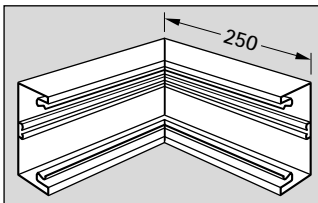


Internal Corner

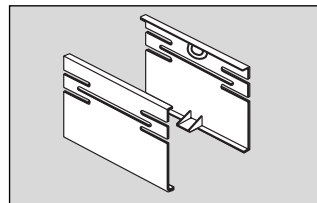


Coupling BR and BRH

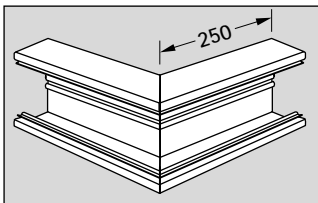


External Corner

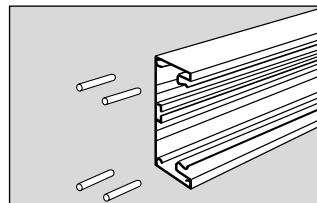


Coupling BRA

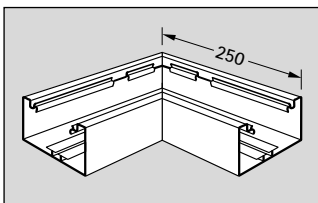


Flat Corner

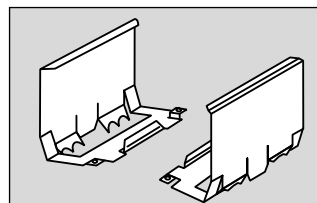


Coupling BRS

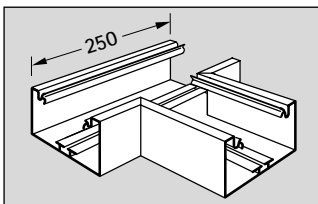


T Piece

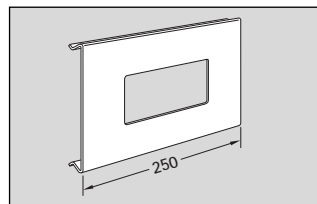


Pre cut lids for double outlet

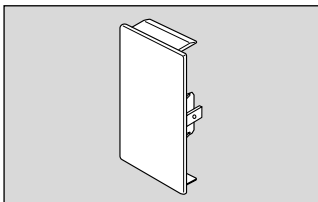


End Cap

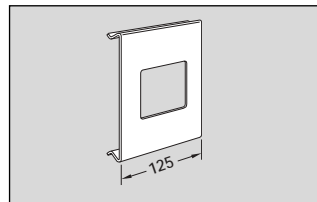

Pre cut lids for single outlet

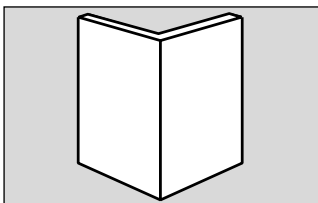

Lid for external corner

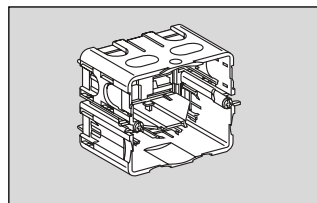

Outlet boxes

BR uPVC dado trunking

- Material uPVC.
- Standard length 2m.
- Up to 2 compartments.
- Base (pre-drilled).

Ordering Information


- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.

Standard colours

- | | |
|------|------------------------|
| 7035 | light grey (RAL 7035). |
| 9010 | pure white (RAL 9010). |

description

*cat
ref.*

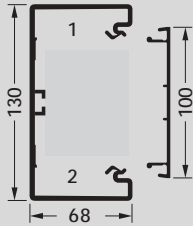

trunking - size: 130mm x 68mm

base only

BR 70130/1/_ _ _ _

lid only

BR 70130/2/_ _ _ _

coupling - comes in 2 pieces

L 2554

end cap

M 5573/_ _ _ _

internal corner

L 8771/_ _ _ _

external corner

L 8772/_ _ _ _

flat corner

L 8775/_ _ _ _

T piece

L 8776/_ _ _ _

lid for external corner

L 8778/_ _ _ _

divider - uPVC

M 1043


pre-cut lids

for double outlet - length 250mm

L 9592/_ _ _ _

for single outlet - length 125mm

L 9600/_ _ _ _

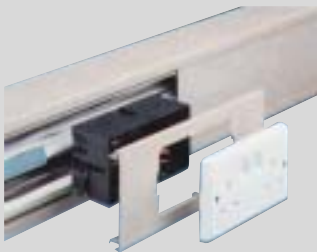

BR uPVC dado trunking

- Material uPVC.
- Standard length 2m.
- Up to 4 compartments.
- Base (pre-drilled).

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.

Standard colours

- | | |
|------|------------------------|
| 7035 | light grey (RAL 7035). |
| 9010 | pure white (RAL 9010). |

description

*cat
ref.*

trunking - size: 170mm x 68mm

base only

BR 70170/1/_____

lid only

BR 70170/2/_____

coupling - comes in 2 pieces

L 2554

end cap

M 5613/_____

internal corner

L 9101/_____

external corner

L 9102/_____

flat corner

L 9105/_____

T piece

L 9106/_____

lid for external corner

L 9288/_____

divider - uPVC

M 1043



pre-cut lids

for double outlet - length 250mm

L 9593/_____

for single outlet - length 125mm

L 9610/_____

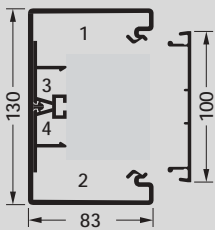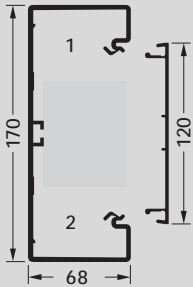

trunking - size: 130mm x 83mm

base only

BR 85130/1/_____

lid only

BR 85130/2/_____

coupling - comes in 2 pieces

L 2354/_____

end cap

L 2353/_____

internal corner

R 8851/_____

external corner

R 8852/_____

flat corner

R 8855/_____

T piece

R 8856/_____

lid for external corner

L 8778/_____

divider - uPVC

M 1043

pre-cut lids

for double outlet - length 250mm

L 9592/_____

for single outlet - length 125mm

L 9600/_____



BR uPVC dado trunking

- Material uPVC.
- Standard length 2m.
- Up to 4 compartments.
- Base (pre-drilled).

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.

Standard colours

- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

description

*cat
ref.*

trunking - size: 170mm x 85mm

base only

BR 85170/1/_ _ _ _

lid only

BR 70170/2/_ _ _ _

coupling - comes in 2 pieces

L 2354

end cap

L 2363/_ _ _ _

internal corner

R 8861/_ _ _ _

external corner

R 8862/_ _ _ _

flat corner

R 8865/_ _ _ _

T piece


R 8866/_ _ _ _

lid for external corner

L 9288/_ _ _ _

divider - uPVC

M 1043

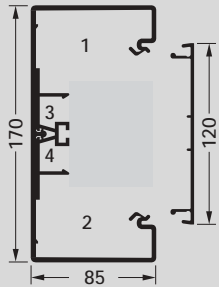


pre-cut lids

for double outlet - length 250mm

L 9593/_ _ _ _

for single outlet - length 125mm

L 9610/_ _ _ _

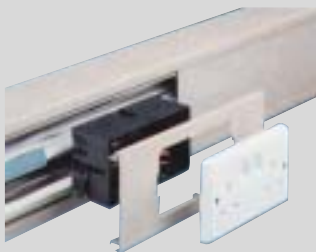

pre-cut lid

trunking sizes BR 70130 and BR 85130

for CEE sockets with 60mm fixing centres

R 8670/_ _ _ _

for CEE sockets with 67mm and 70mm fixing centres

R 8671/_ _ _ _

pre-cut lid

trunking sizes BR 70170 and BR 85170

for CEE sockets with 60mm fixing centres

R 8672/_ _ _ _

for CEE sockets with 67mm and 70mm fixing centres

R 8673/_ _ _ _



Future proofed flexible cable management system for school

Both present cabling needs and spare capacity for future power and data have been catered for during the refurbishment of Bell Baxter High School in Cupar, Fife, with the installation of Tehalit's four compartment BR trunking.



Two compartments in the BR trunking are used for power and data cabling with two left spare to allow for future cabling upgrades with no or minimal disruption.

With the school establishing a strong IT presence across its site, a cable management system for flexible distribution of power and data was deemed essential.

Different finishes of trunking have been used in different areas for aesthetics. Most of the areas have a neutral white finish but the CDT area has used a galvanised finish to match the ductwork and pipes that have been left exposed as a feature.

BRH halogen free plastic dado trunking

- Material PC/ABS.
- Standard length 2m.
- Up to 2 compartments.
- Base (pre-drilled).


Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box

Standard colours


- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

<i>description</i>	<i>cat ref.</i>
--------------------	-----------------

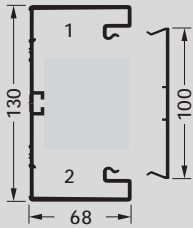

trunking - size: 130mm x 68mm

base only	BRH 70132/1/_----
lid only	BRH 70132/2/_----
coupling - comes in 2 pieces	L 2554
end cap	L 2833/_-----
internal corner	R 7931/_-----
external corner	R 7932/_-----
flat corner	R 7935/_-----
T piece	R 7936/_-----
lid for external corner	R 7939/_-----
divider - PC/ABS	M 1839

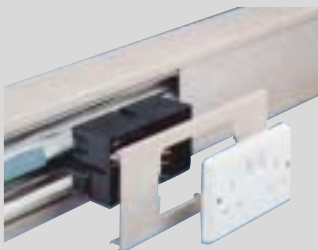


pre-cut lids

for double outlet - length 250mm	R 6484/_-----
for single outlet - length 125mm	R 6501/_-----

trunking - size: 170mm x 68mm

base only	BRH 70172/1/_----
lid only	BRH 70172/2/_----
coupling	L 2554
end cap	L 2873/_-----
internal corner	R 7971/_-----
external corner	R 7972/_-----
flat corner	R 7975/_-----
T piece	R 7976/_-----
lid for external corner	R 7979/_-----
divider - PC/ABS	M 1839

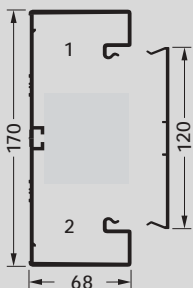

pre-cut lids

for double socket - length 250mm	R 6494/_-----
for single socket - length 125mm	R 6511/_-----

Fife's four compartment flexible future looks good with fins

Fife council offices have met their need for future cabling flexibility and aesthetics with Tehalit's four compartment BR cable management system and matching fin grills over radiators.



The council is using two of the four compartments in the Tehalit BRA system for power and data and has left two compartments spare to allow for future cabling upgrades with minimal disruption.

Different floors and different wings in the building have used Tehalit BR in either a natural or white powder coated finish depending on the décor.

The BRA trunking is wall mounted using adjustable fixing brackets. This eases installation when the walls are not true. Matching aluminium fin grills were mounted onto the brackets to mask the top of radiators. The fin louvres are angled to allow heat to rise through them, which allows a continuous trunking run at desktop height without overheating. It also ensures that radiators are set flush to the trunking and improves the aesthetics.

Both finned grills and finned panels that run from the trunking to the floor are available as accessories with Tehalit BR, BRA, BRH, C60 or CA60 cable management systems.



BRA aluminium dado trunking

- Material: Aluminium.
- Standard length 2m.
- Up to 2 compartments.

Ordering Information


- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours

- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

Other Finishes

- Alunat natural anodised.

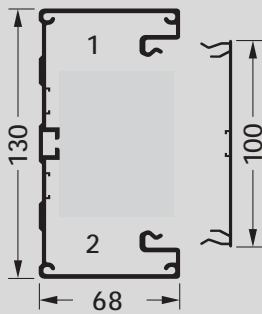

description


*cat
ref.*

trunking - size: 130mm x 68mm

base only	BRA 70132/1/_ _ _ _
lid only	BRA 70132/2/_ _ _ _
coupling pins	L 5412
end cap	L 6133/_ _ _ _
IP54 end cap	L 6134/_ _ _ _
internal corner	R 9701/_ _ _ _
external corner	R 9702/_ _ _ _
flat corner	R 9705/_ _ _ _
T piece	R 9706/_ _ _ _
lid for external corner	R 7529/_ _ _ _
divider - PC/ABS	M 1839

pre-cut lids

for double socket - length 250mm	R 6852/_ _ _ _
for single socket - length 125mm	R 9501/_ _ _ _

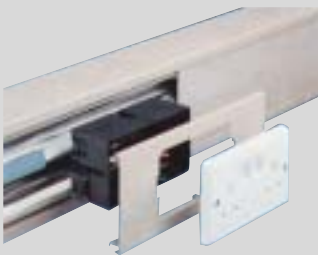

BRA aluminium dado trunking

- Material: Aluminium.
- Standard length 2m.
- Up to 2 compartments.

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours

- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

Other Finishes

- Alunat natural anodised.

description

*cat
ref.*

trunking - size: 170mm x 68mm

base only

BRA 70172/1/_----

lid only

BRA 70172/2/_----

coupling pins

L 5412

end cap

L 6143/_----

IP54 end cap

L 6144/_----

internal corner

R 9711/_----

external corner

R 9712/_----

flat corner

R 9715/_----

T piece

R 9716/_----

lid for external corner

R 7539/_----

divider - PC/ABS

M 1839

pre-cut lids

for double outlet - length 250mm

R 6862/_----

for single outlet - length 125mm

R 9511/_----

trunking - size: 210mm x 68mm

base only

BRA 70212/1/_----

lid only

BRA 70172/2/_----

coupling pins

L 5412

end cap

L 4813/_----

internal corner

R 7041/_----

external corner

R 7042/_----

flat corner

R 7045/_----

T piece

R 7046/_----

lid for external corner

R 7539/_----

divider - PC/ABS

M 1839




pre-cut lids

for double outlet - length 250mm

R 6862/_----

for single outlet - length 125mm

R 9511/_----

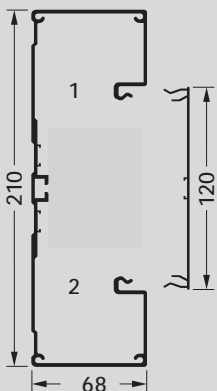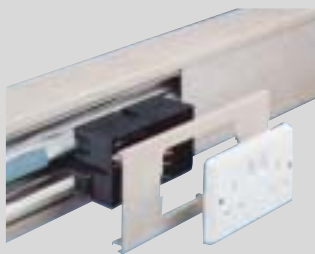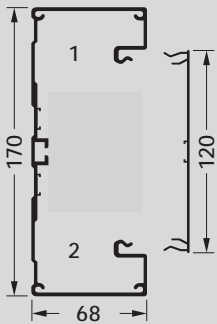

BRA aluminium dado trunking

- Material: Aluminium.
- Standard length 2m.
- Up to 4 compartments.

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours

- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

Other Finishes

- Alumat natural anodised.

<i>description</i>	<i>cat ref.</i>
--------------------	-----------------

trunking - size: 130mm x 83mm

base only	BRA 85132/1/_----
lid only	BRA 70132/2/_----
coupling pins	L5412
end cap	L 6583/_----
internal corner	R 9721/_----
external corner	R 9722/_----
flat corner	R 9725/_----
T piece	R 9726/_----
lid for external corner	R 7529/_----
divider - PC/ABS	M 1839

pre-cut lids



for double outlet - length 250mm	R 6852/_----
for single outlet - length 125mm	R 9501/_----

trunking - size: 170mm x 83mm

base only	BRA 85172/1/_----
lid only	BRA 70172/2/_----
coupling pins	L5412
end cap	L 6593/_----
internal corner	R 9731/_----
external corner	R 9732/_----
flat corner	R 9735/_----
T piece	R 9736/_----
lid for external corner	R 7539/_----
divider - PC/ABS	M 1839

pre-cut lids

for double outlet - length 250mm	R 6862/_----
for single outlet - length 125mm	R 9511/_----

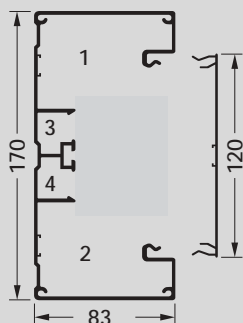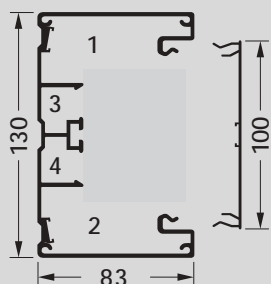

BRA aluminium dado trunking

description

*cat
ref.*

**pre-cut lid
trunking sizes BRA 70132 and BRA 85132**

for CEE sockets with 60mm fixing centres

R 9508/_ _ _ _

for CEE sockets with 67mm and 70mm fixings

R 9509/_ _ _ _


**pre-cut lid
trunking sizes BRA 70172, BRA 85172 and BRA 70212**

for CEE sockets with 60mm fixing centres

R 9518/_ _ _ _

for CEE sockets with 67mm and 70mm fixings

R 9519/_ _ _ _

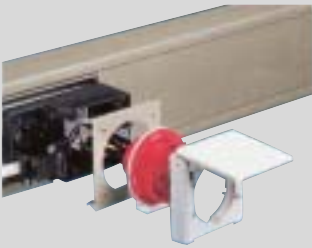

BRS steel dado trunking

- Material: galvanised steel.
- Standard length 2m.
- Up to 2 compartments.
- Base (pre-drilled).

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours


- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

Other Finish

- VERZ galvanised.

description

*cat
ref.*

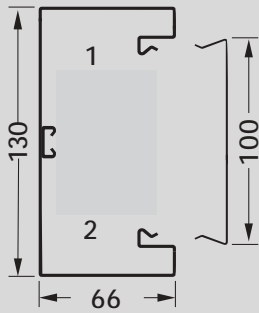


trunking - size: 130mm x 66mm

base only	BRS 70132/1/_ _ _ _
lid only	BRS 70132/2/_ _ _ _
coupling	L 2219
end cap	L 9453/_ _ _ _
internal corner	R 6411/_ _ _ _
external corner	R 9802/_ _ _ _
flat corner	R 9805/_ _ _ _
T piece	R 9806/_ _ _ _
lid for external corner - steel	R 9808/_ _ _ _
divider - steel	G 1613

pre-cut lids

for double outlet - length 250mm	R 6092/_ _ _ _
for single outlet - length 125mm	R 9301/_ _ _ _

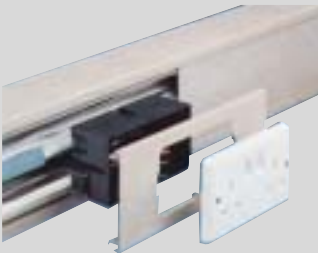

BRS steel dado trunking

- Material: galvanised steel.
- Standard length 2m.
- Up to 2 compartments.
- Base (pre-drilled).

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours

7035 light grey (RAL 7035).
9010 pure white (RAL 9010).

Other Finish

VERZ galvanised.

description

*cat
ref.*

trunking - size: 170mm x 66mm

base only

BRS 70172/1/_----

lid only

BRS 70172/2/_----

coupling - comes in 2 pieces

L 2209

end cap

L 9463/_----

internal corner

R 6421/_----

external corner

R 9812/_----

flat corner

R 9815/_----

T piece


R 9816/_----

lid for external corner

R 9818/_----

divider - steel

G 1613

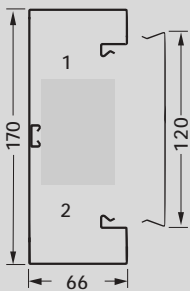

trunking - size: 210mm x 66mm

base only

BRS 70212/1/_----

lid only

BRS 70172/2/_----

coupling - comes in 2 pieces

L 2217

end cap

L 9483/_----

internal corner

R 6431/_----

external corner

R 9822/_----

flat corner

R 9825/_----

T piece


R 9826/_----

lid for external corner

R 9818/_----

divider - steel

G 1613

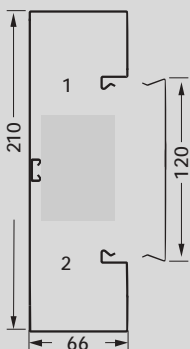


pre-cut lids

for double outlet - length 250mm

R 6122/_----

for single outlet - length 125mm

R 9311/_----

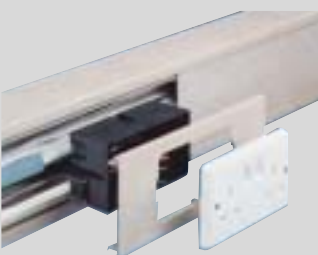

BRS steel dado trunking

- Material Base: galvanised steel.
- Standard length 2m.
- Up to 4 compartments.
- Base (pre-drilled).

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours

- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

Other Finish

- VERZ galvanised.

description

*cat
ref.*

trunking - size: 130mm x 83mm

base only

BRS 85132/1/_----

lid only

BRS 70132/2/_----

coupling - comes in 2 pieces

L 4854

end cap

R 7123/_----

internal corner

R 7171/_----

external corner

R 7172/_----

flat corner

R 7175/_----

T piece

R 7176/_----

lid for external corner

R 9808/_----

divider - steel

G 1613

pre-cut lids

for double outlet - length 250mm

R 6092/_----

for single outlet - length 125mm

R 9301/_----

trunking - size: 170mm x 83mm

base only

BRS 85172/1/_----

lid only

BRS 70172/2/_----

coupling - comes in 2 pieces

L 4864

end cap

R 7133/_----

internal corner

R 7181/_----

external corner

R 7182/_----

flat corner

R 7185/_----

T piece

R 7186/_----

lid for external corner

R 9818/_----

divider - steel

G 1613





pre-cut lids

for double outlet - length 250mm

R 6122/_----

for single outlet - length 125mm

R 9311/_----

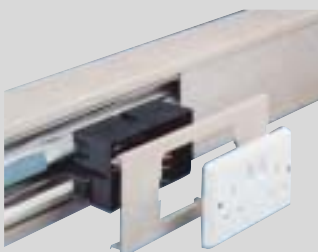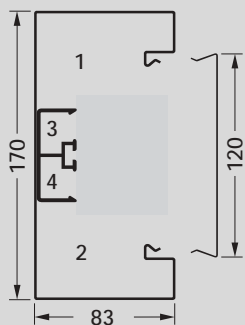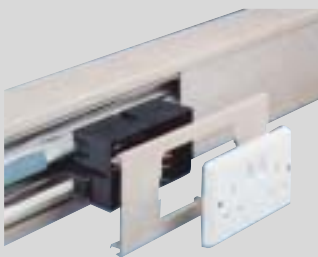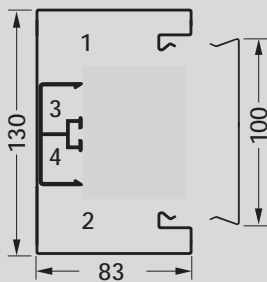

BRS steel dado trunking

- Material Base: galvanised steel.
- Standard length 2m.
- Up to 4 compartments.
- Base (pre-drilled).

Ordering Information

- Base and lid to be ordered separately.
- When ordering please add the RAL reference number to the part number.
- A pre-cut lid is needed for every outlet box.
- For earthing see accessories section (page 21).

Standard colours


- 7035 light grey (RAL 7035).
- 9010 pure white (RAL 9010).

Other Finish

- VERZ galvanised.

description

*cat
ref.*

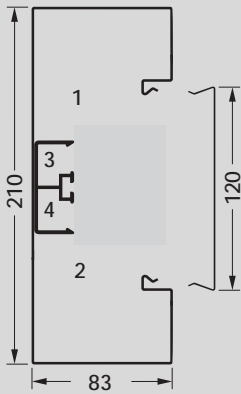

trunking - size: 210mm x 83mm

base only	BRS 85212/1/_ _ _ _
lid only	BRS 70172/2/_ _ _ _
coupling - comes in 2 pieces	L 4874
end cap	R 7153/_ _ _ _
internal corner	R 7201/_ _ _ _
external corner	R 7202/_ _ _ _
flat corner	R 7205/_ _ _ _
T piece	R 7206/_ _ _ _
lid for external corner - steel	R 9818/_ _ _ _
divider - steel	G 1613

pre-cut lids



for double outlet - length 250mm	R 6122/_ _ _ _
for single outlet - length 125mm	R 9311/_ _ _ _

pre-cut lid trunking size **BRS 70132 - BRS 85132**

CEE sockets with 60mm fixing centres	R 9338/_ _ _ _
CEE sockets with 67mm and 70mm fixing centres	R 9339/_ _ _ _

pre-cut lid trunking size **BRS 70172 - BRS 85172** - **BRS 85212 - BRS 70212**

CEE sockets with 60mm fixing centres	R 9368/_ _ _ _
CEE sockets with 67mm and 70mm fixing centres	R 9369/_ _ _ _

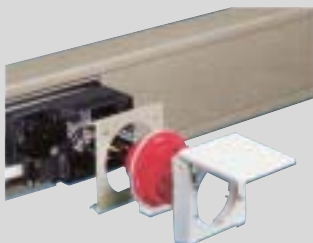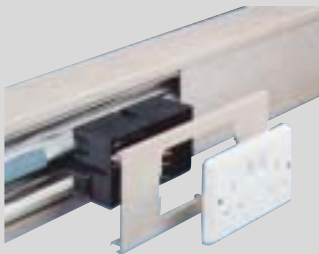

BR/BRA/BRS/BRH


accessories

The following accessories are available for the BR/BRH/BRS and BRA range of dado trunking.

- dividers.
- cable retaining clips.
- fins.
- locking system.
- earthing components.
- mounting brackets.




Partition

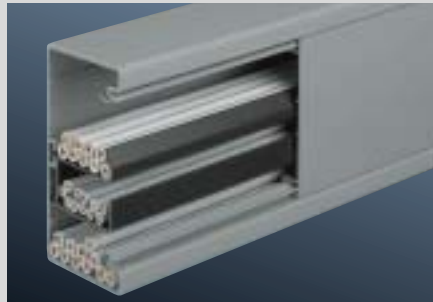


Double partition




Steel Partition

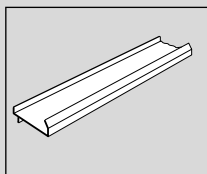

M 1043
Material uPVC
black
2 m lengths

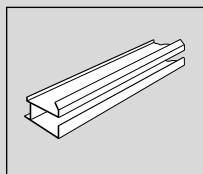


M 1257
Material: uPVC
black
2m lengths

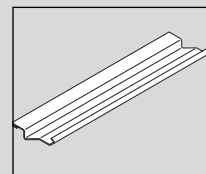

G 1613
Material:
galvanised steel
2m lengths




Cable Retainers

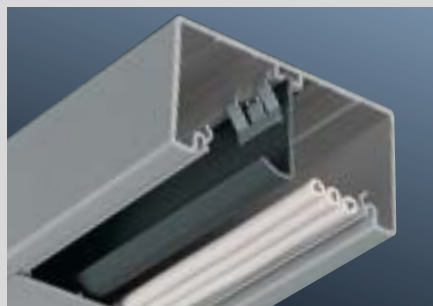

Partition Retainer




End Cap (IP54)

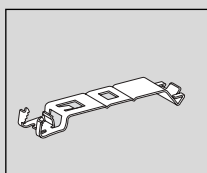


Cable retainers
L 4254
to fit 100mm lid (size)


L 4255
to fit 120mm lid (size)

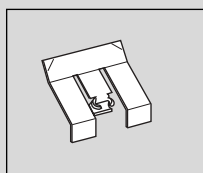

L 6705
To be used when the
trunking is installed
vertically or
overhead.

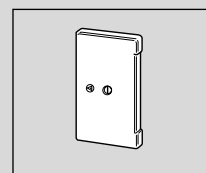

L 6134/_____
for BR 70130
BRA/BRS 70132

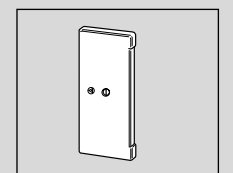


L 6144/_____
for BR 70170
BRA/BRS 70172

Note: can be used
to secure lid to
the base when
combined with
L9616
M5 nut insert

When used with BRA,
trunking can achieve IP54.
Consult us for more information



Compartment lid

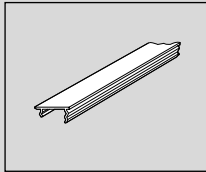


L 6497
for internal
compartment of
BRA 85132 & 85172
BRS 85132/85172
BRS 85212

Material: Aluminium
2 m lengths

Note: will not fit BR




Compartment lid

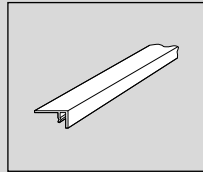


M 1663
for internal
compartment of
BR 85130/85170
BRA 85132/85172
BRS 85132/85172
BRS 85212

Material: uPVC
2 m lengths

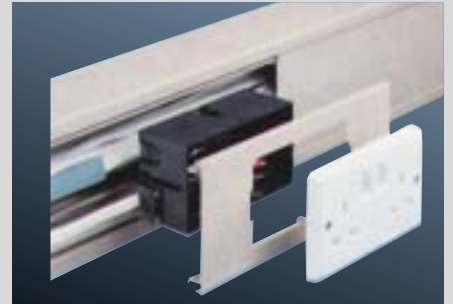


Outlet box

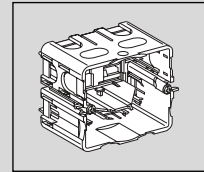


L 2619
double outlet box
L 2618
single outlet box
L 5819
CEE outlet box

Colour: black

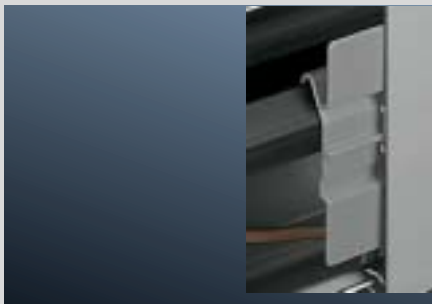


BR-clip 130

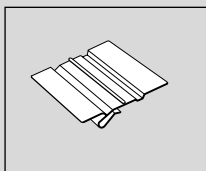


M 5840
for BR 70130/85130
BRA/BRS 70132
BRA/BRS 85132

Material:
Polystyrene grey

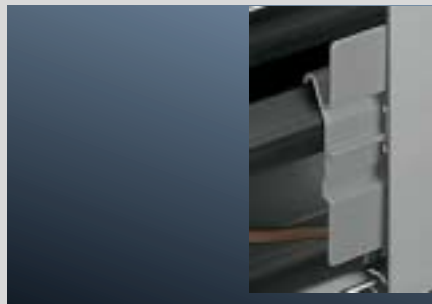


BR-clip 170

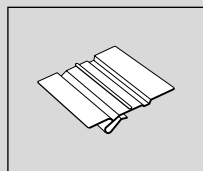


M 5841
for BR 70170/85170
BRA/BRS
70172/70212
BRA/BRS 85172/
BRS 85212

Material:
Polystyrene grey

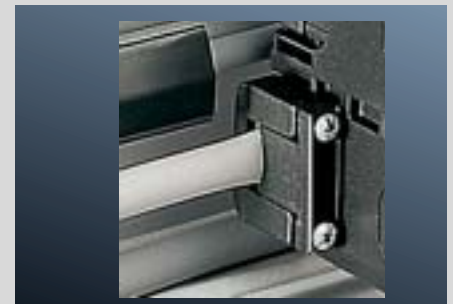

Cable grip

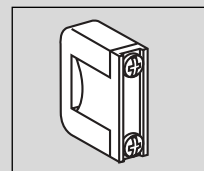

M 5861
Secures cable to the
outlet box.

BRA aluminium




Earthing


Earth protection - equipotential bonding

Bases and lids (including pre-cut lids) must be installed with earthing terminals to satisfy earthing and equipotential bonding requirements throughout the whole installation.


This is easily achieved as shown below:

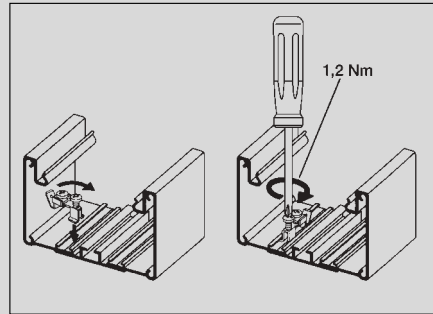


Lid earthing.

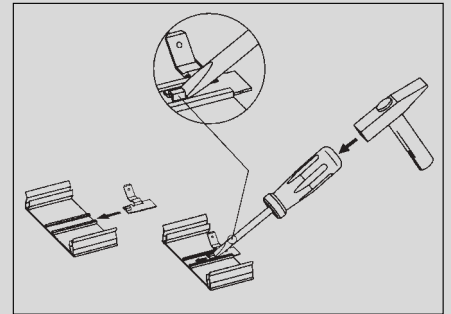

Base earthing.

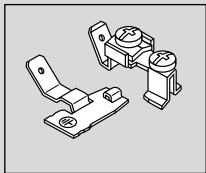

BRA-earth terminal
L 5802
 Material: Steel
 Base and lid earthing kit for BRA

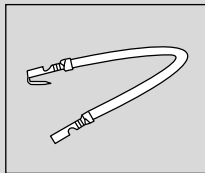

Earth strap
Part no. length
 L 4181 150mm
 L 4182 300mm
 L 4183 600mm

BRS Steel


Earth protection - equipotential bonding

Bases and lids (including pre-cut lids) must satisfy earthing and equipotential bonding requirements throughout the whole installation. This can be achieved by using the following components;


The BRS coupling piece can be used to connect base to base.




Base earthing

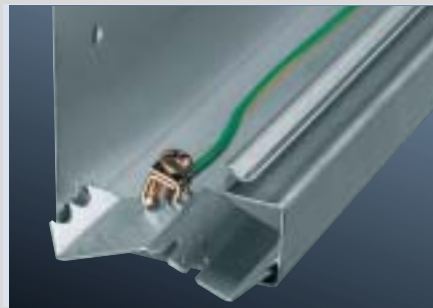


Base earthing

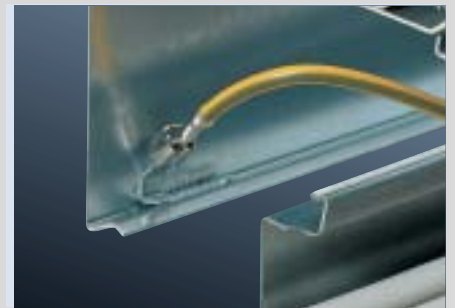


Lid earthing

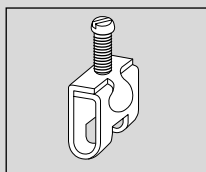


Earth terminal
L 4187
 Can be used with
 R 6570 and R 6585

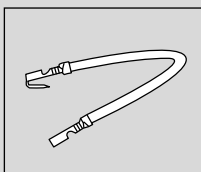


Earth strap
Part no. length
 L 4181 150mm
 L 4182 300mm
 L 4183 600mm

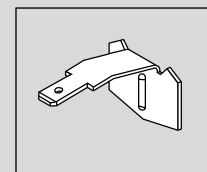

Earth tag
L 4180
 for BRS partition

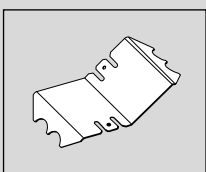

Earth Connector
Part no. Height
 R 6570 66mm
 R 6585 83mm
 R 6600 100mm

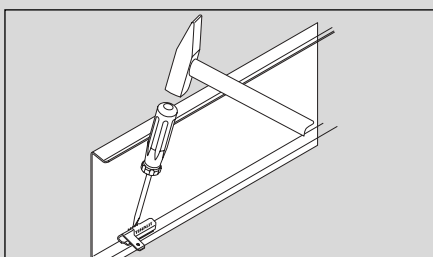

BRS lid tag
L 6699

The use of fins and brackets can ease installation and minimise the need for countless corners or additional fabrication on site. The system can be used to hide radiators, pipework and unsightly or awkward posts, without compromising access.



Adjustable bracket

**Adjustable bracket**

- Fixed directly to the mounting surface.
- The simple design permits alignment of brackets after the trunking installation.
- Provides mounting surface for fin supports.
- Available for depths of 38 to 500mm.

The use of mounting brackets provides an alternative option to mounting the base direct to the wall surface.

Fin supports

**Fin supports**

- Used to secure and maintain correct spacing of fins.
- The grill has a solid appearance at viewing angles of up to 70°.
- Easily cut to size.
- To be mounted onto supporting tube and mounting bracket.


Fin grills

**Fin grills**

- Easily detached for cleaning and repair
- 65% air passage.
- Appears solid up to viewing angles of 70°.
- Protective cover plate offering unimpeded air circulation.
- Robust will withstand normal loads with bracket spacing of 0.66m.



Adjustable bracket for 130mm depth trunking

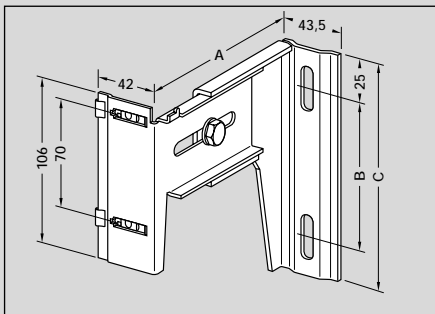

	A	B	C
L 6691	38-55	55	102.5
L 6692	50-78	55	102.5
L 6693	70-115	55	102.5
L 6694	105-160	95	145
L 6695	150-240	95	145
L 6696	230-360	95	145
L 6697	350-500	95	145


(all dimensions in mm)

For trunking size

BR 70130 BRA 70132 BRS 70132
 BR 85130 BRA 85132 BRS 85132
 BRH 70132



Adjustable bracket for 170 - 210mm depth trunking

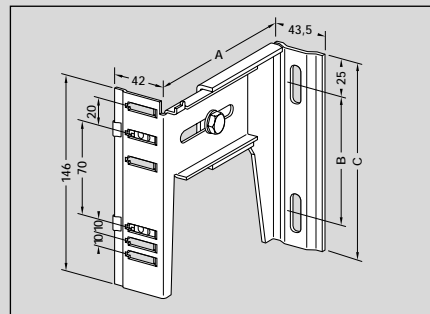


	A	B	C
L 6791	38-55	55	
L 6792	50-78	55	102.5
L 6793	70-115	55	102.5
L 6794	105-160	95	145
L 6795	150-240	95	145
L 6796	230-360	95	145
L 6797	350-500	95	145

(all dimensions in mm)


For trunking size

BR 70170 BRA 70172 BRS 70172
 BR 85170 BRA 85172 BRS 85172
 BRH 70172 BRA 70212 BRS 70212
 C60 CA60 BRS 85212

Used to fix the trunking base to the mounting bracket. Two bolts required for each bracket

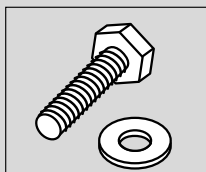


Bolt & washer
 M 5 x 20mm
 L 6467

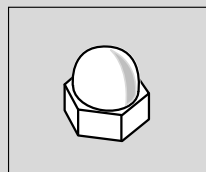

L 6468
 Plastic cap for L6467



Fin support and supporting tube

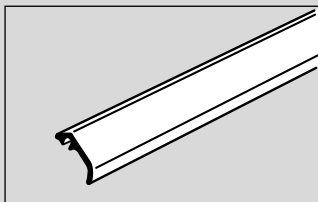


Fin
L 6450/_ _ _ _
Material aluminium

Standard length: 2m

Can be cut to length or joined together as required.


Note: remember to add the required colour information

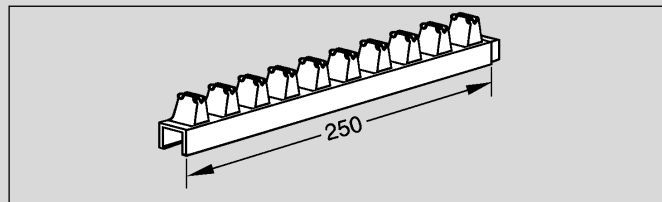

Fin support
M 5900/7021
M 5900/7035


Support for 10 fins

To be mounted onto supporting tube and mounting bracket.

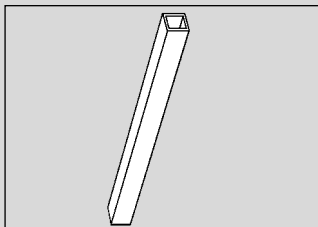


Supporting tube
L 6991
For vertical fin/grill

Standard length: 2m
Material: Steel

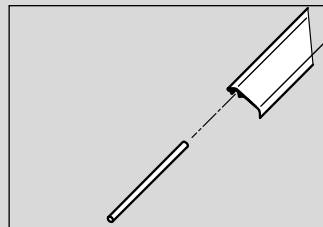

Coupling pin for fins
L 5412
To join fin lengths.

1 pin for 2 lengths.

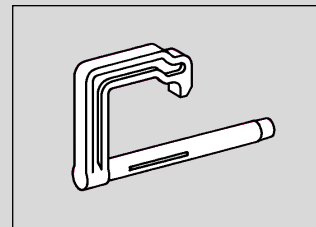

Securing clip for fins
M 5919

To secure the fin support to the mounting bracket.

Kit for fin system

Trunking type

BR/BRA/BRS/BRH
with a depth of up to 70mm
i.e. BR70170/1/_ _ _ _

L 6990


BR/BRA/BRS
with a depth of up to 85mm
i.e. BRA85172/1/_ _ _ _

L 6880

C60/CA60
i.e. CU601/W

L 4170

Note: One kit is required for every two support tubes.

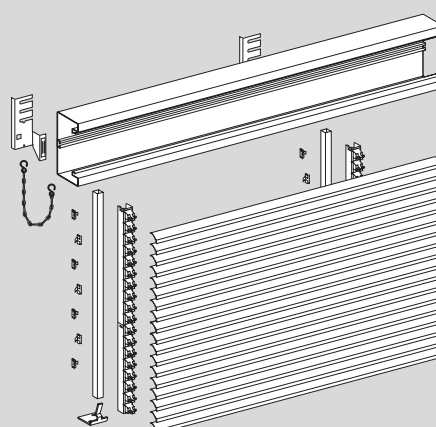

Comprising of:

- 2 magnetic retainers.
- 2 floor attachment.
- clips to secure fin support to the supporting tube.
- screws to fix floor attachments.
- chain.
- lever.

Installation Example

1 Determine Brackets

- 1.1. Select bracket type.
Depending on trunking type and distance from wall.
- 1.2 Determine number of brackets.
Dependent on trunking length.
One bracket recommended every 0.66m.



2 Determine the fin requirements,
dependent on,

- 2.1 Space between floor to trunking and length of area to be covered.
- 2.2 Determine number of supporting tubes.
We recommend to use one supporting tube for every 0.66m.
Supporting tubes are delivered in standard length of 2000mm.
- 2.3 Determine type of kit for fins, dependent on the trunking type.
Select one kit for every two supporting tubes.



3 Horizontal or vertical fins

- 3.1 Horizontal fins.
 - 3.1.1. Determine number of fin supports (horizontal) :
Dependent on the number of brackets and the distance from wall.
One fin support is 250mm.
 - 3.1.2 Determine length of fins (horizontal):
One fin per 25mm. Clipped onto fin support.
Fins are delivered in standard length of 2000mm.




3.2. Vertical fins



- 3.2.1. Determine number of fin supports (vertical):
Dependent on the length and number of supporting tubes.
One fin support is 250mm.
- 3.2.2 Determine length of fins (vertical):
One fin per 25mm. Clipped onto fin support.
Fins are delivered in standard length of 2000mm.



List of parts needed

Pos.	description	cat. ref.	amount	unit
1	Type and amount of brackets			Piece.
2	Length and amount of supporting tubes			Piece.
3	Type and amount of kits for panel system			Piece.
4	Number of fin supports for horizontal use			Piece.
5	Length of fins used for horizontal use			Metre
6	Number of fin supports for vertical use			Piece.
7	Length of fins used for vertical use			Metre.

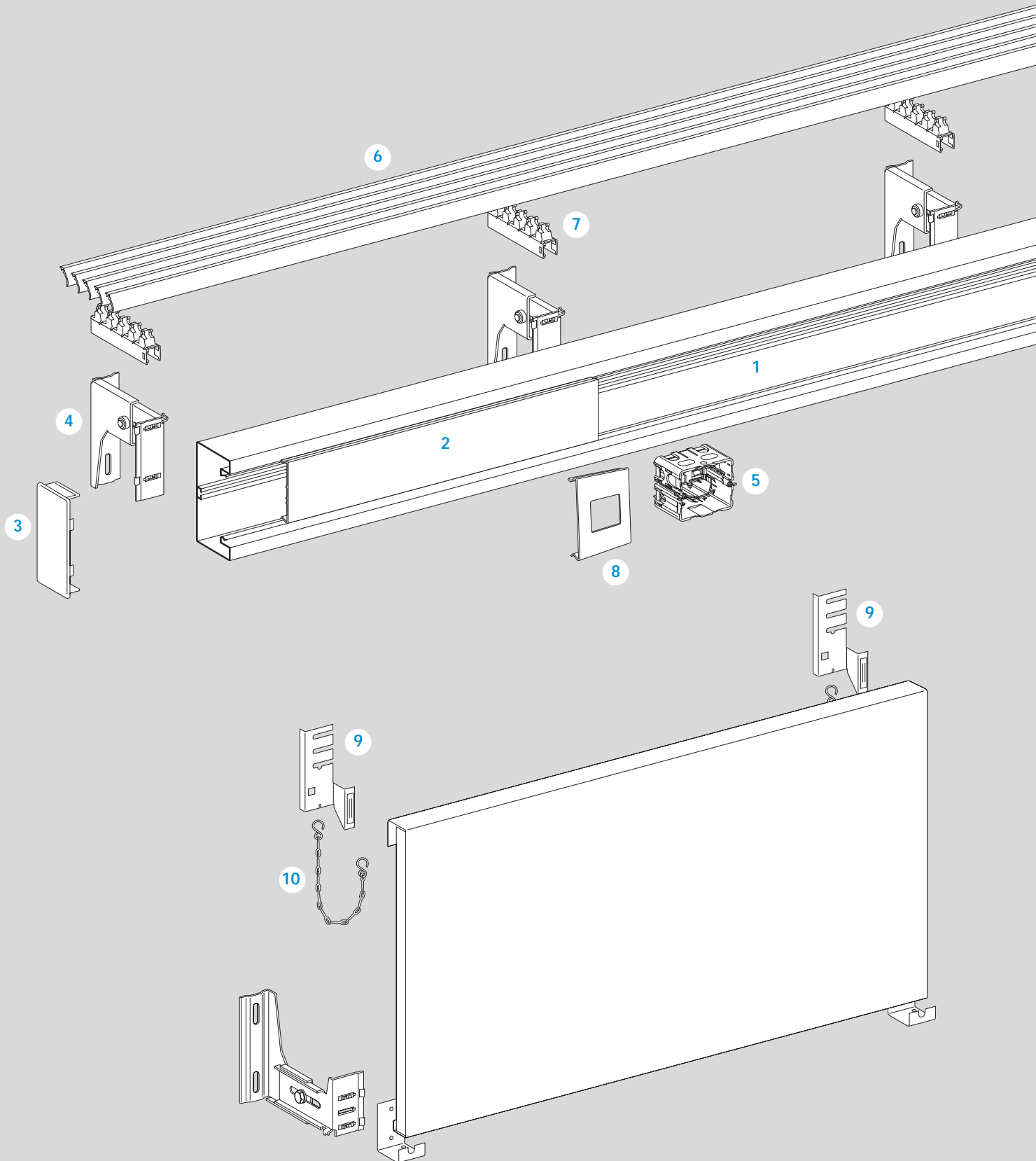

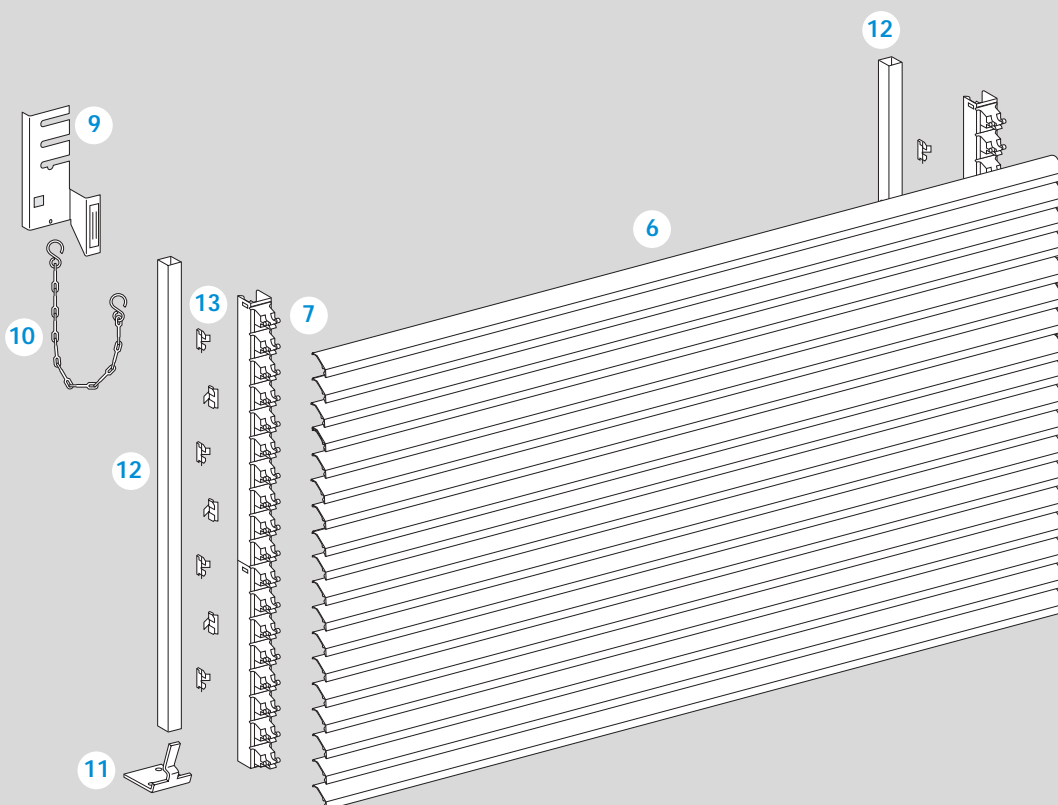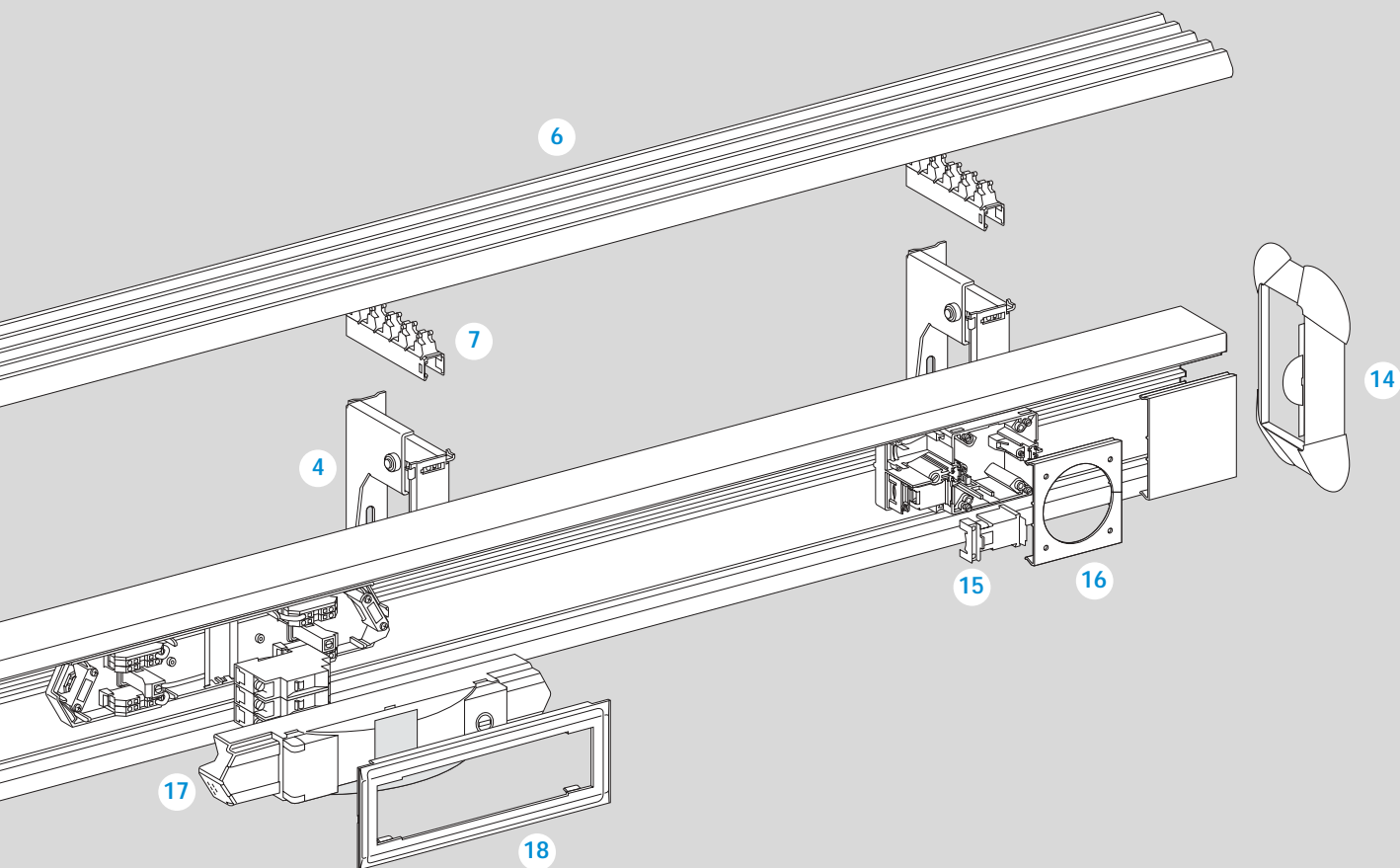

- | | | | | | |
|---|---------------------|----|---------------------|----|------------------------------|
| 1 | dado trunking. | 7 | fin support. | 13 | clips. |
| 2 | trunking lid. | 8 | pre-cut lid. | 14 | flange. |
| 3 | end cap. | 9 | magnetic retainers. | 15 | CEE socket box. |
| 4 | adjustable bracket. | 10 | chain. | 16 | CEE pre-cut lid. |
| 5 | outlet box. | 11 | floor attachment. | 17 | MCB housing, 3 gang. |
| 6 | fin. | 12 | supporting tube. | 18 | lid for MCB housing, 3 gang. |

product reference	qty	page n°	product reference	qty	page n°	product reference	qty	page n°	product reference	qty	page n°
BR			L			M			R		
BR 70130/1/_	8m	5	L 5412	100	11,12,	M 5861	50	20	R 9301/_	1	15,17
BR 70130/2/_	24m	5			13,25	M 5900/7021	10	25	R 9311/_	1	16,17,
BR 70170/1/_	8m	6	L 5819	1	20	M 5900/7035	10	25			18
BR 70170/2/_	24m	6,7				M 5919	50	25	R 9338/_	1	18
BR 85130/1/_	8m	6	L 6133/_	5	11				R 9339/_	1	18
BR 85130/2/_	24m	6	L 6134/_	10	11,19	R			R 9368/_	1	18
BR 85170/1/_	8	7	L 6143/_	5	12	R 6092/_	1	15,17	R 9369/_	1	18
			L 6144/_	10	12,19	R 6122/_	1	16,17,	R 9501/_	1	11,13
			L 6450/_	100m	25			18	R 9508/_	1	14
BRA			L 6467	100	23	R 6411/_	8	15	R 9509/_	1	14
BRA 70132/1/_	8m	11	L 6468	100	23	R 6421/_	6	16	R 9511/_	1	12,13
BRA 70132/2/_	24m	11,13	L 6497	100m	20	R 6431/_	6	16	R 9518/_	1	14
BRA 70172/1/_	8m	12	L 6583/_	5	13	R 6484/_	1	9	R 9519/_	1	14
BRA 70172/2/_	24m	12,13	L 6593/_	5	13	R 6494/_	1	9	R 9701/_	8	11
BRA 70212/1/_	8m	12	L 6691	10	23	R 6501/_	1	9	R 9702/_	5	11
BRA 85132/1/_	8m	13	L 6692	10	23	R 6511/_	1	9	R 9705/_	12	11
BRA 85172/1/_	8m	13	L 6693	10	23	R 6570	10	21	R 9706/_	4	11
			L 6694	10	23	R 6585	10	21	R 9711/_	6	12
BRH			L 6695	10	23	R 6600	10	21	R 9712/_	4	12
BRH 70132/1/_	8m	9	L 6696	10	23	R 6852/_	1	11,13	R 9715/_	10	12
BRH 70132/2/_	24m	9	L 6697	10	23	R 6862/_	1	12,13	R 9716/_	4	12
BRH 70172/1/_	8m	9	L 6699	25	21				R 9721/_	1	13
BRH 70172/2/_	24m	9				R 7041/_	5	12	R 9722/_	5	13
						R 7042/_	3	12	R 9725/_	10	13
BRS			L 6705	10	19	R 7045/_	8	12	R 9726/_	4	13
BRS 70132/1/_	8m	15	L 6791	10	23	R 7046/_	10	12	R 9731/_	6	13
BRS 70132/2/_	16m	15,17	L 6792	10	23	R 7123/_	1	17	R 9732/_	4	13
BRS 70172/1/_	8m	16	L 6793	10	23	R 7133/_	5	17	R 9735/_	8	13
BRS 70172/2/_	16m	16,17,	L 6794	10	23	R 7153/_	1	18	R 9736/_	9	13
		18	L 6795	10	23	R 7171/_	7	17			
BRS 70212/1/_	8m	16	L 6796	10	23	R 7172/_	5	17	R 9802/_	5	15
BRS 85132/1/_	8m	17	L 6797	10	23	R 7175/_	10	17	R 9805/_	12	15
BRS 85172/1/_	8m	17				R 7176/_	5	17	R 9806/_	5	15
BRS 85212/1/_	8m	18	L 6880	1	24	R 7181/_	6	17	R 9808/_	5	15,17
			L 6990	1	24	R 7182/_	4	17	R 9812/_	4	16
G			L 6991	8m	25	R 7185/_	8	17	R 9815/_	10	16
G 1613	32m	19				R 7186/_	5	17	R 9816/_	5	16
			L 8771/_	8	5	R 7201/_	4	18	R 9818/_	20	16,17,
L			L 8772/_	5	5	R 7202/_	2	18			18
L 2209	5	16	L 8775/_	12	5	R 7205/_	6	18	R 9822/_	6	16
L 2217	5	16	L 8776/_	4	5	R 7206/_	3	18	R 9825/_	1	16
L 2219	5	15	L 8778/_	5	5,6	R 7529/_	5	11	R 9826/_	5	16
L 2353/_	5	6				R 7539/_	5	12,13			
L 2354	5	6,7	L 9101/_	6	6	R 7931/_	1	9			
L 2363/_	5	7	L 9102/_	4	6	R 7932/_	1	9			
L 2554	5	5,6,9	L 9105/_	14	6	R 7935/_	1	9			
L 2618	5	20	L 9106/_	4	6	R 7936/_	1	9			
L 2619	5	20	L 9288/_	5	6,7	R 7939/_	5	9			
L 2833/_	5	9	L 9453/_	1	15	R 7971/_	1	9			
L 2873/_	5	9	L 9463/_	1	16	R 7972/_	1	9			
			L 9483/_	1	16	R 7975/_	1	9			
L 4170	1	24	L 9592/_	1	5,6	R 7976/_	1	9			
L 4180	50	21	L 9593/_	1	6,7	R 7979/_	5	9			
L 4181	10	21	L 9600/_	1	5,6						
L 4182	10	21	L 9610/_	1	6,7	R 8670/_	1	7			
L 4183	10	21				R 8671/_	1	7			
L 4187	10	21	M			R 8672/_	1	7			
L 4254	1	19	M 1043	40m	19	R 8673/_	1	7			
L 4255	1	19	M 1663	100m	20	R 8851/_	7	6			
L 4813/_	1	12	M 1257	40m	19	R 8852/_	5	6			
L 4854	5	17	M 1839	40m	9,11,	R 8855/_	10	6			
L 4864	5	17			12,13	R 8856/_	4	6			
L 4874	5	18				R 8861/_	6	7			
			M 5573/_	5	5	R 8862/_	4	7			
			M 5613/_	5	6	R 8865/_	8	7			
			M 5840	50	20	R 8866/_	9	7			
			M 5841	50	20						

The BR ranges of dado trunking form part of Tehalit's cable management offer. Other product ranges include:

C60 / CA60
Perimeter Systems



Now available in 3 lengths

SL
Slimline Skirting Trunking



Specifying the system to suit your project, or ordering the necessary components really couldn't be easier. However, if you need any assistance please consult our sales or technical helpline.

Sales Hotline
e-mail:

0870 240 2400
sales@hager.co.uk

Technical Helpline
e-mail:

0870 607 6677
technical@hager.co.uk

LF/LFS
General Purpose Trunking



LFG
High Strength GRP Trunking




Should you require a sales visit or require further information with reference to a **particular project** please complete your details and return to us, via the attached reply paid card.

Pacpole and Pacpost
Powerpoles and Powerposts



Panel Trunking
Slotted Trunking

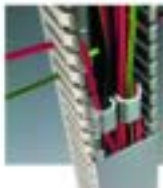

Information regarding the products featured in this brochure can be found on our website:

www.hager.co.uk

We also have a range of Halogen Free systems suitable for use where self-extinguishing low flammability and minimal release of gases are essential. Typical areas include public buildings, schools, and hospitals.



Bristol Regional Centre

135 Aztec West
Almondsbury
Bristol
BS32 4UB
Tel: 01454 616245
Fax: 01454 617172

Falkirk Regional Centre

5a Callendar Business Park
Callendar Road
Falkirk
FK1 1XR
Tel: 01324 632128
Fax: 01324 631294

London Regional Centre

Warwick House
65-66 Queen Street
London
EC4R 1EB
Tel: 0207 3293891
Fax: 0207 3293893

Midlands Regional Centre

Hortonwood 50
Telford
Shropshire
TF1 7FT
Tel: 01952 675615
Fax: 01952 675626

Wakefield Regional Centre

Brindley Way
Wakefield 41 Ind. Estate
Wakefield
West Yorkshire
WF2 0XQ
Tel: 01924 871103
Fax: 01924 824429

Visit our website:

www.hager.co.uk

e-mail us @

info@hager.co.uk
sales@hager.co.uk
technical@hager.co.uk

Ireland

Hager Ltd.
Unit M2 Furry Park
Industrial Estate,
Santry,
Dublin 9.
Ireland.

From ROI

Tel: 1890 551 502
Fax: 1890 551 503

From NI

Tel: 028 90 773310
Fax: 028 90 773572

Email: info@hager.ie
Web: <http://www.hager.ie>



National Sales Hotline
0870 240 2400

National Technical Support Helpline
0870 607 6677

National Sales Faxline
0870 240 0400

Visit our website:
www.hager.co.uk

e-mail us @
info@hager.co.uk
sales@hager.co.uk
technical@hager.co.uk