

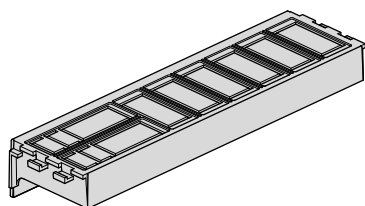



6LE002346A

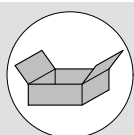






Vision




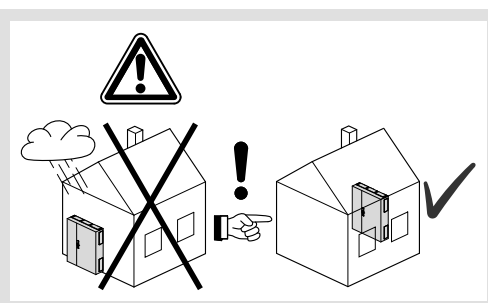


VKG82T

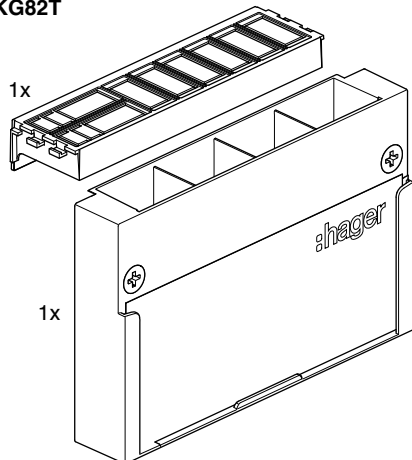


VKG85T

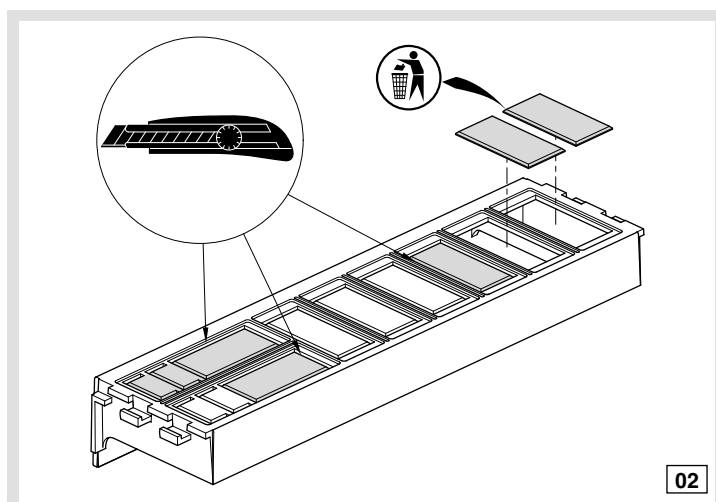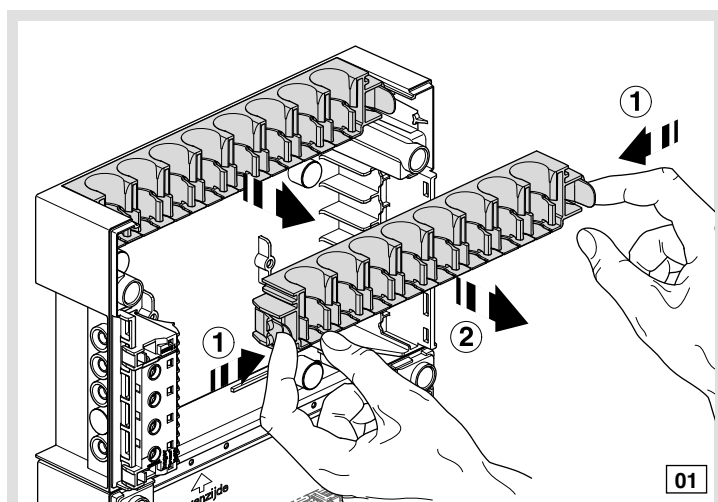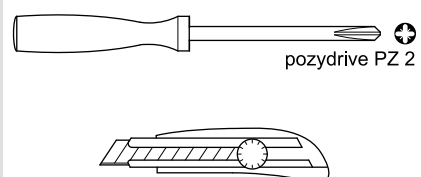
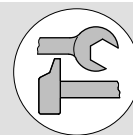
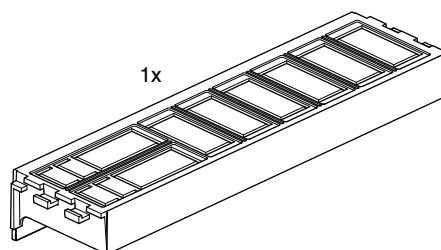


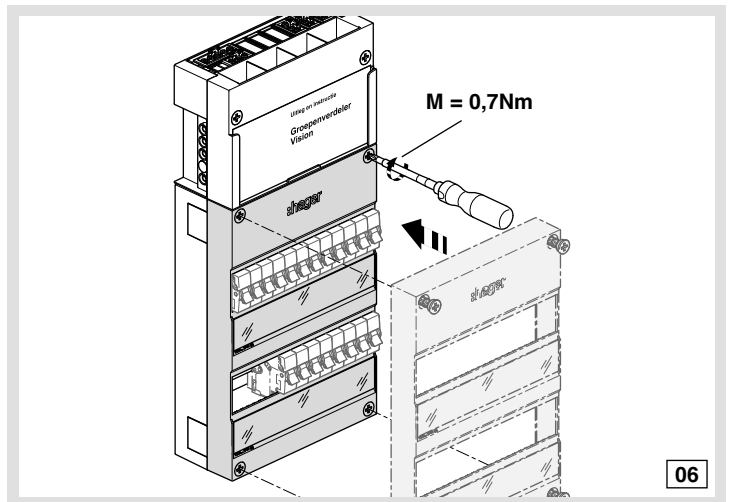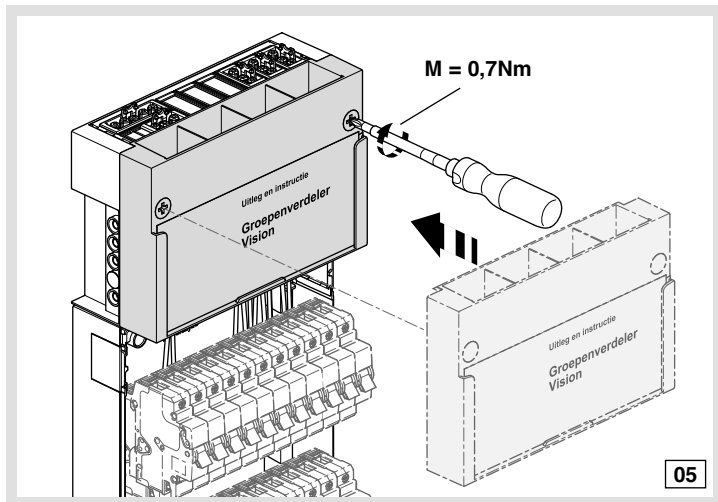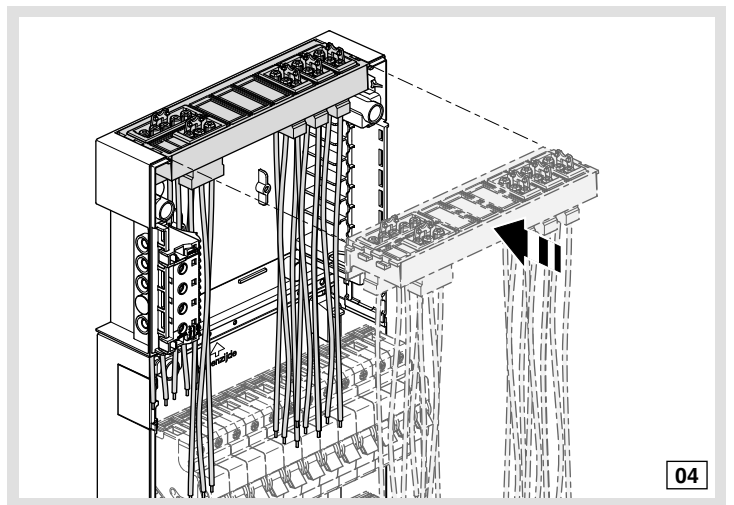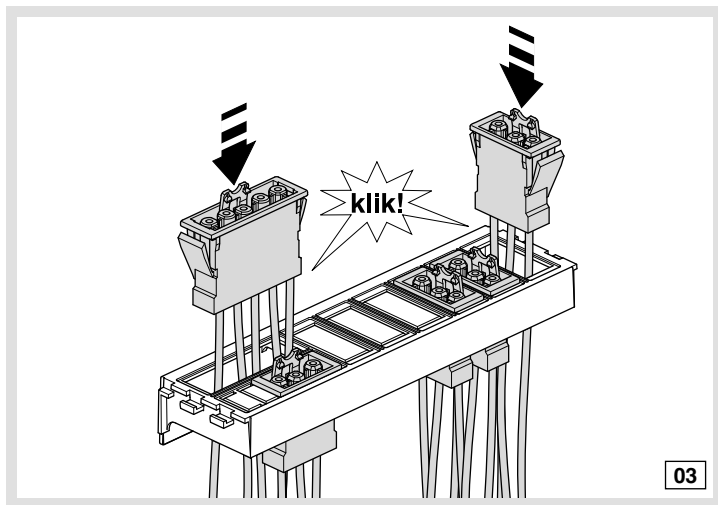


6LE002839A

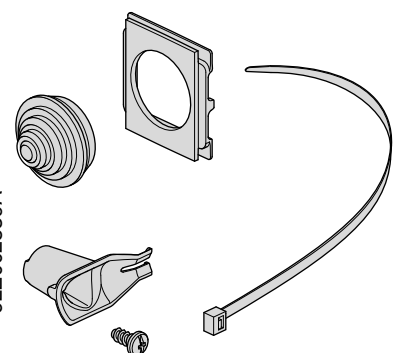


Vision

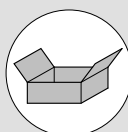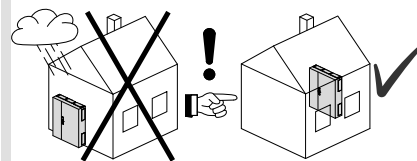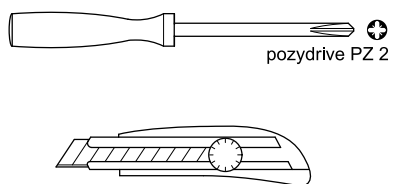


VKG70T

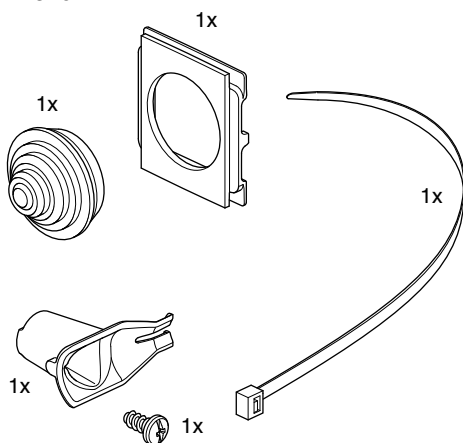


VKG71T

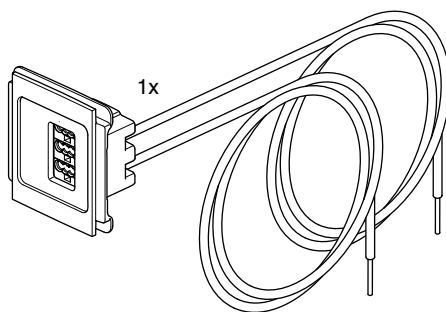


VKG72T

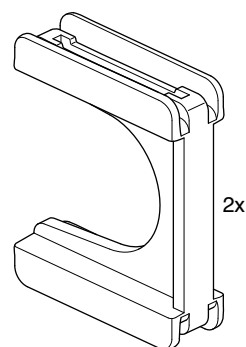


VKG73T

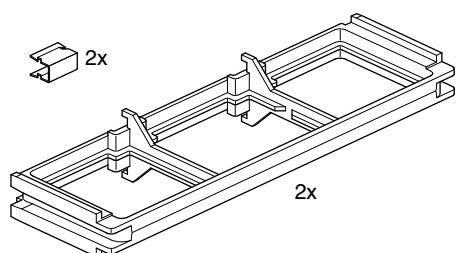


VKG74T

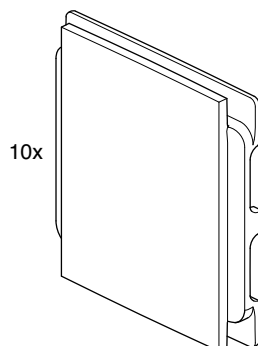


VKG75T/ VKG76T

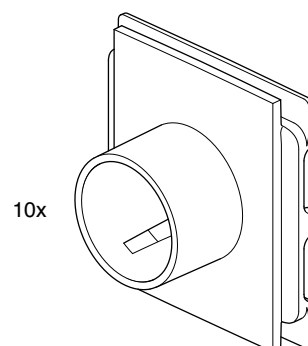


VKG77T

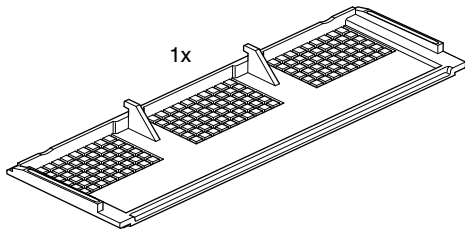







VKG78T

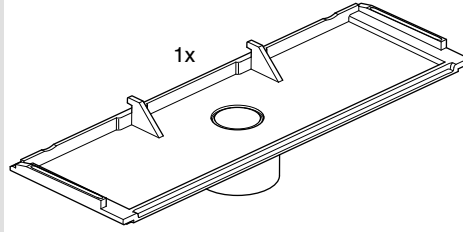


VKG79T

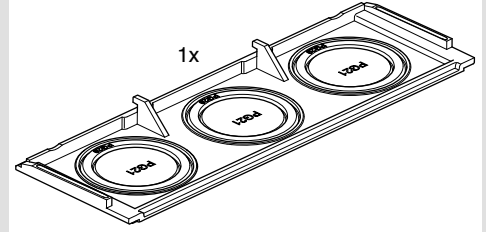


VKG70T

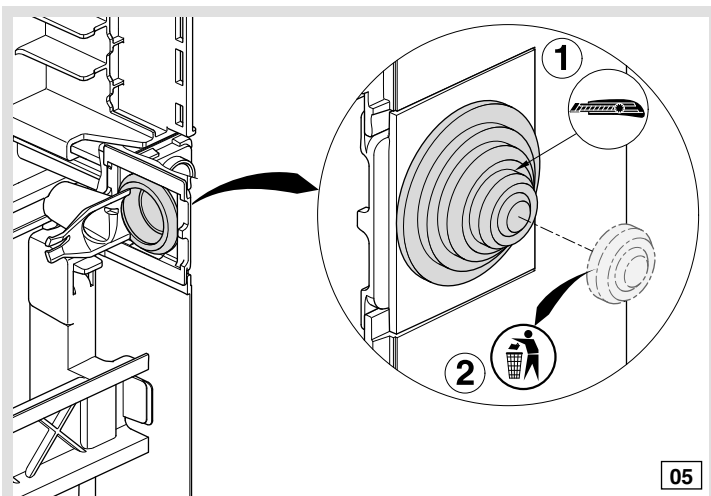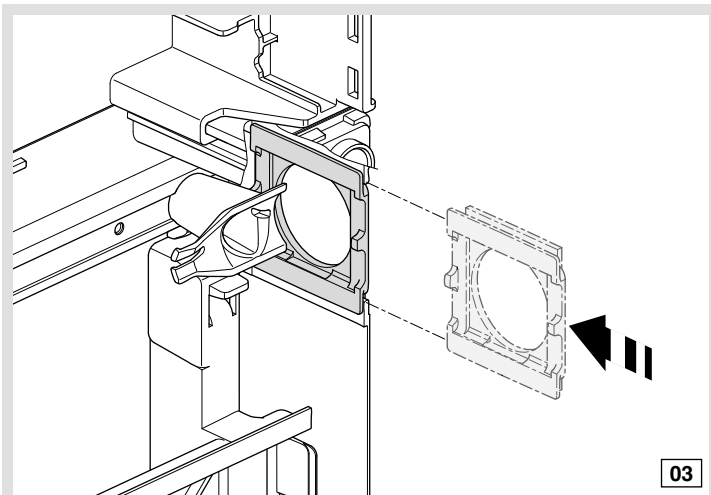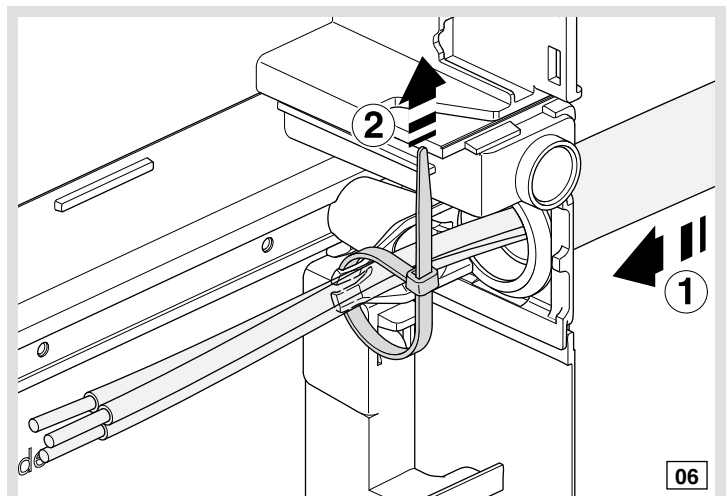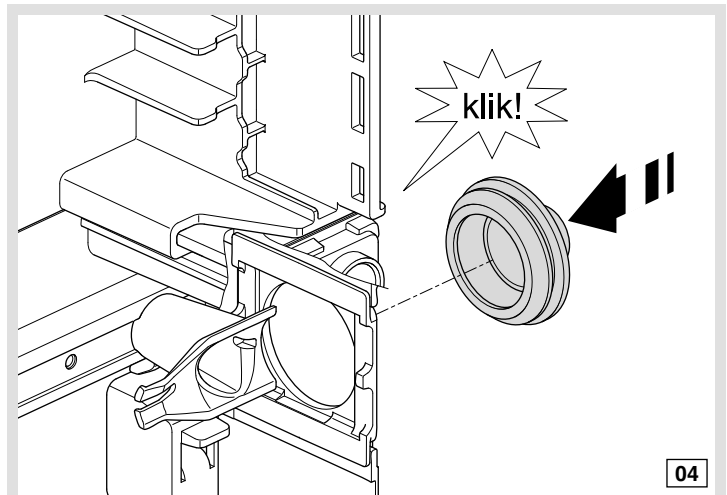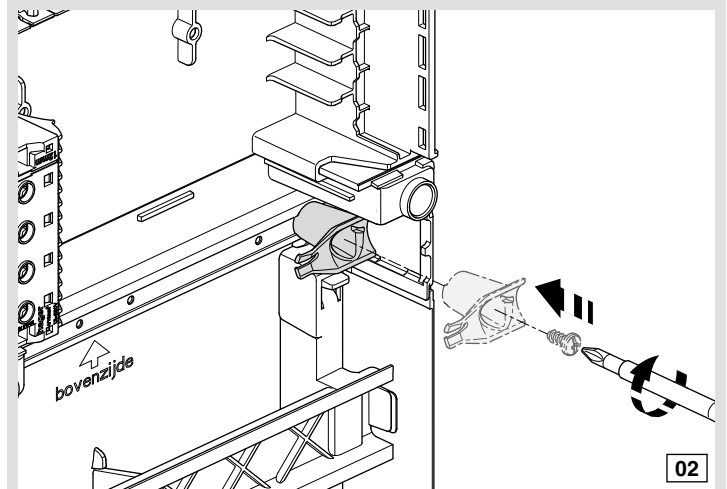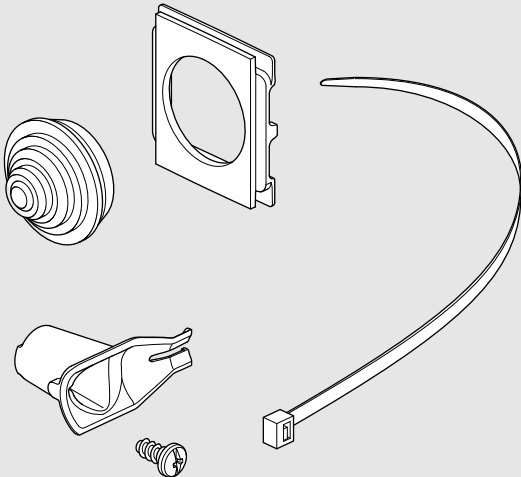

VKG71T

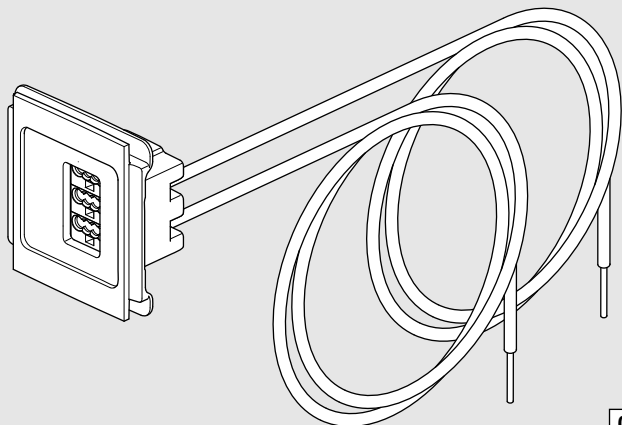

07

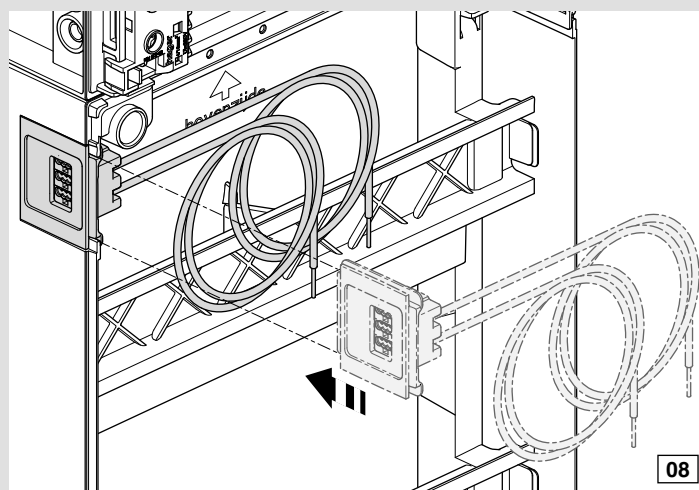


08


VKG72T, 2x

VKG75T, 10x

VKG76T, 10x

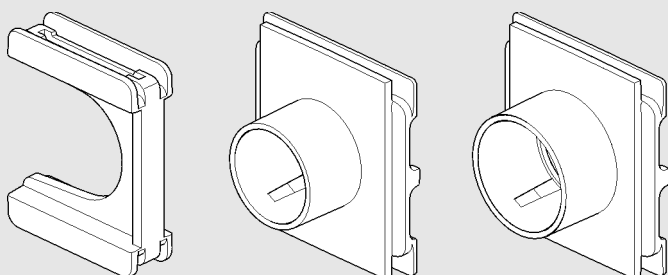


09

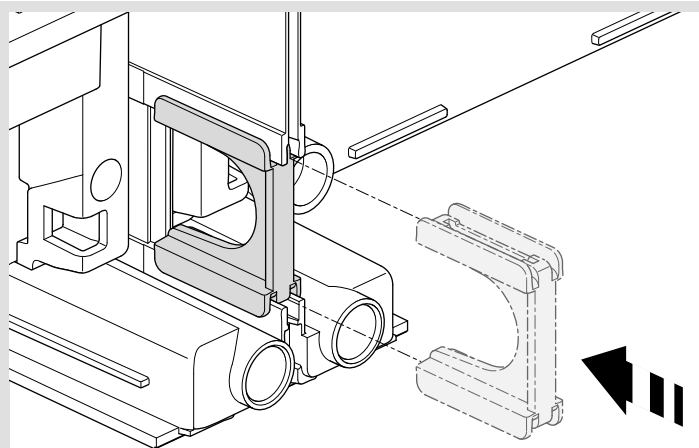


VKG72T

10

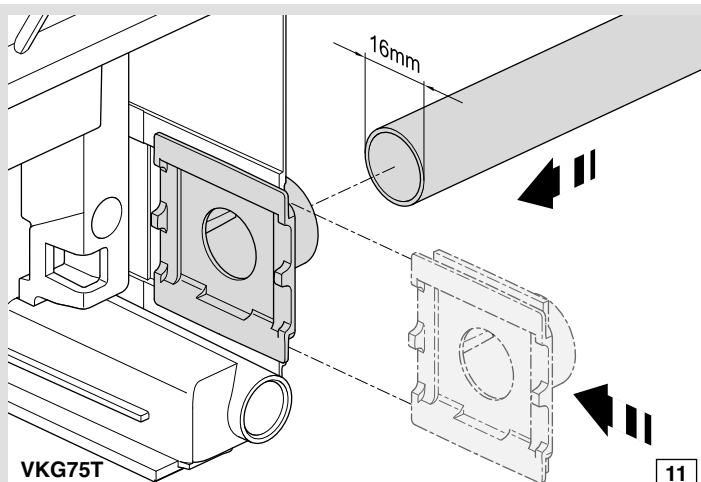

VKG75T


11

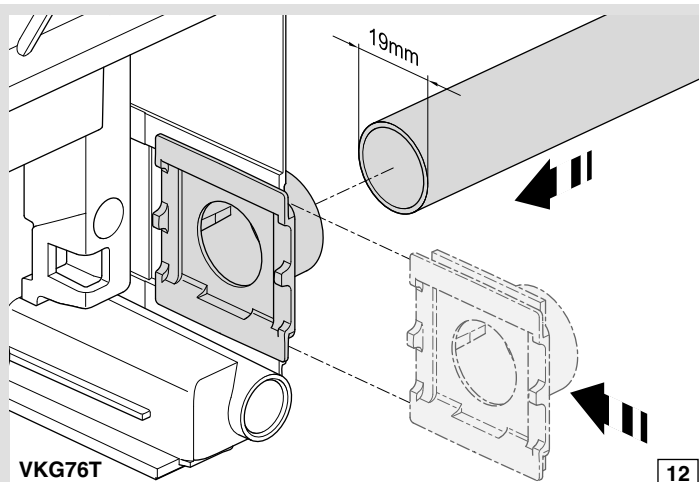


VKG76T

12



VKG73T

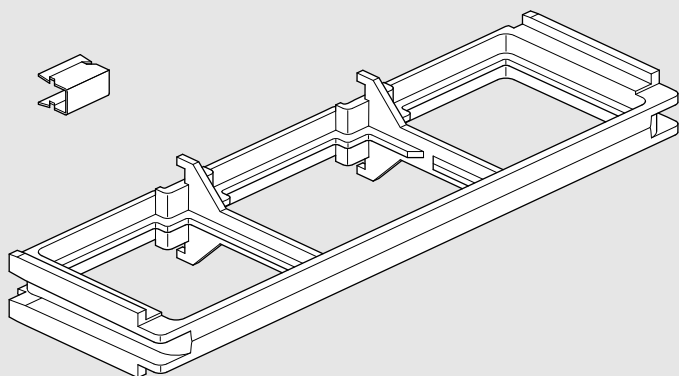



13

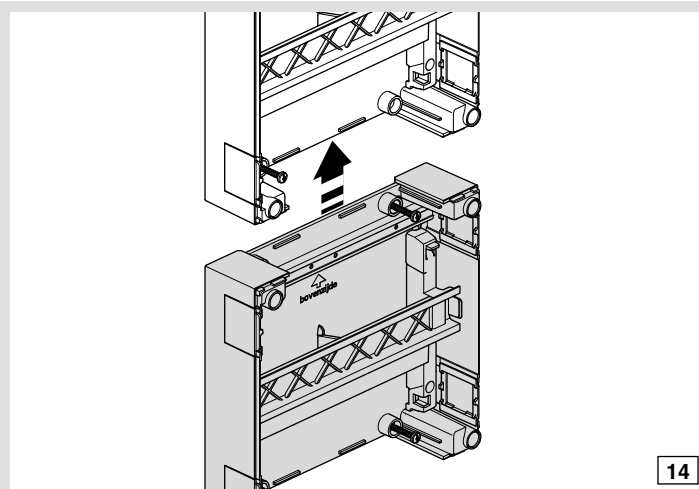



14

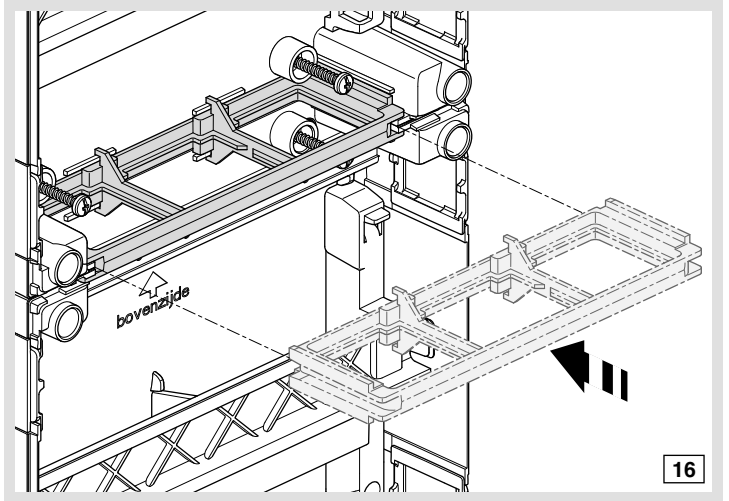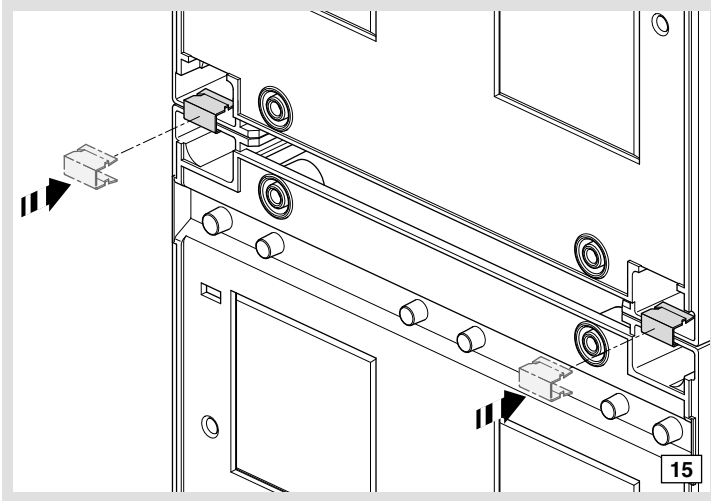



VKG74T

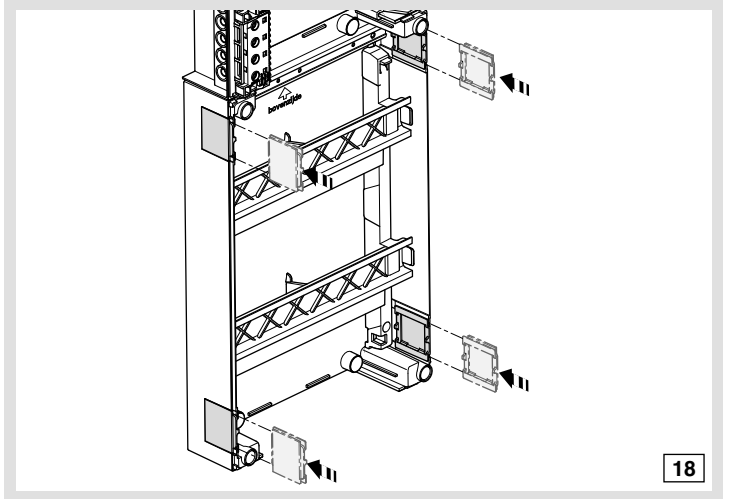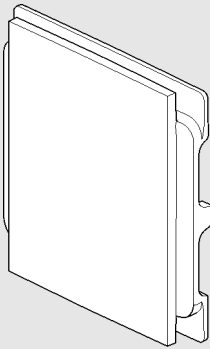


VKG77T

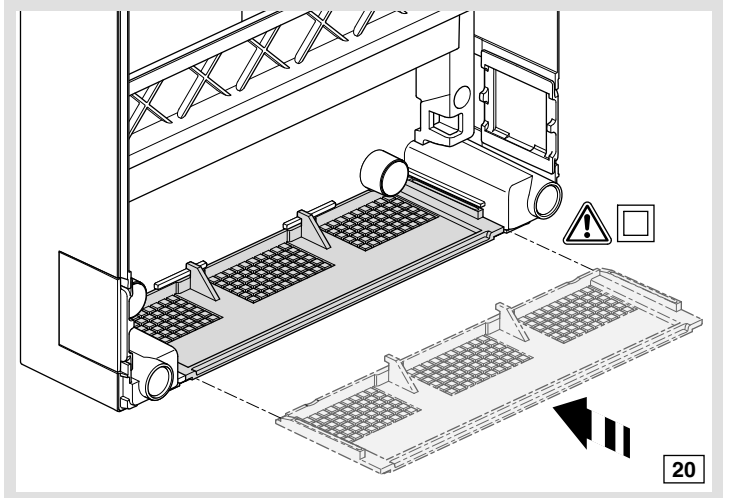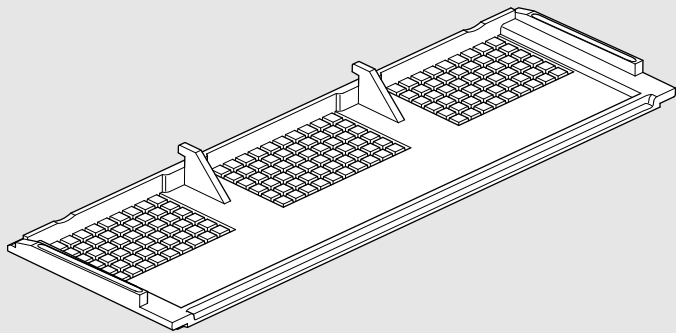


VKG78T

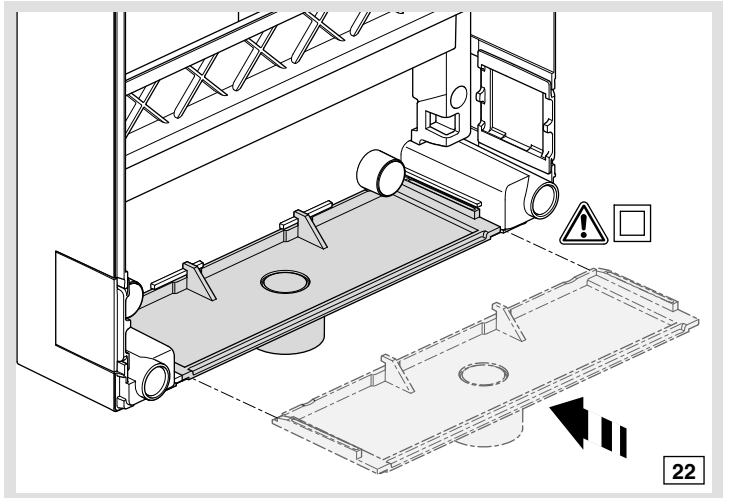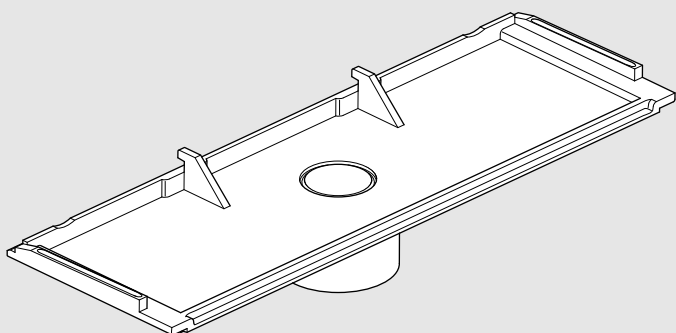

VKG79T

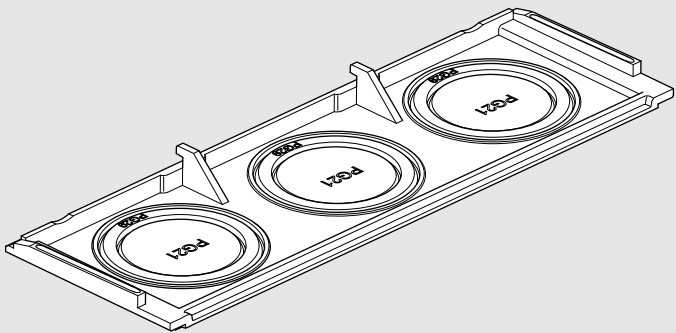


23

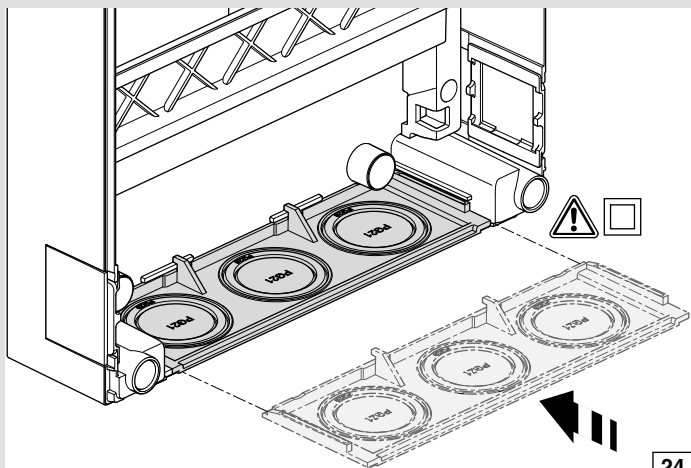

24

(NL) Gebruiksaanwijzing
(DE) Montageanleitung




(FR) Notice d'instructions
(GB) Mounting instructions

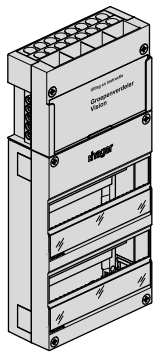


Vision

VKG21S, 40A / 230V
VKG22S, 40A / 400V
VKG23S, 40A / 400V
VKG21Z, 40A / 230V
VKG22Z, 40A / 400V


EN 60670-24 (PD)

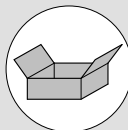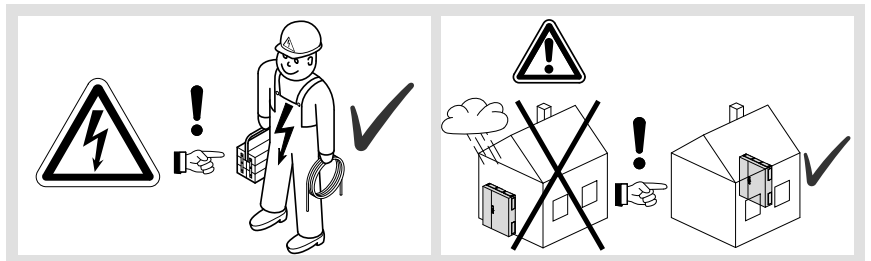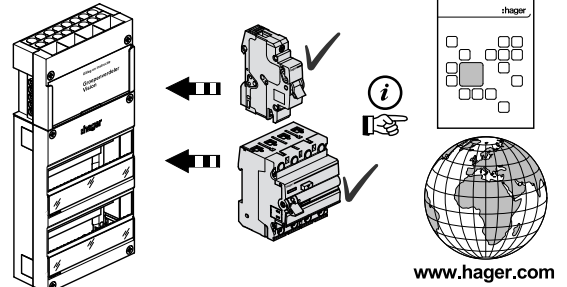


VKG21S

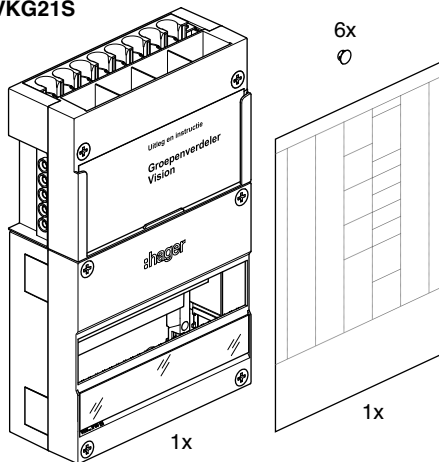


VKG22S

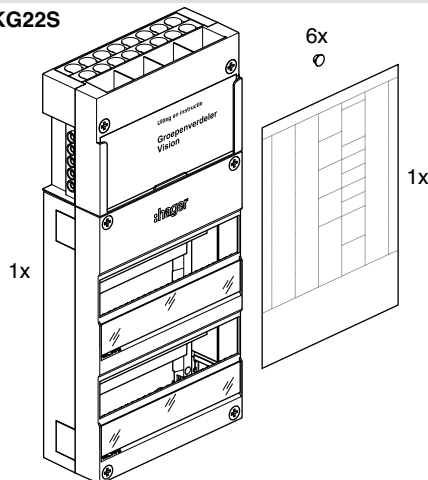

VKG23S

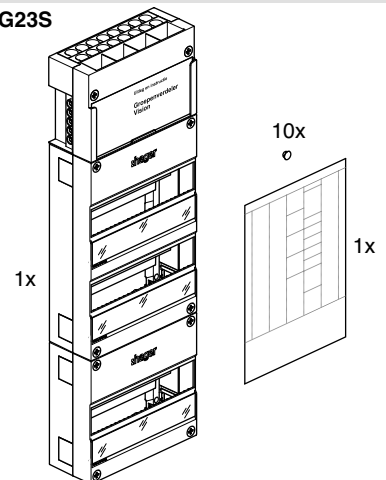

VKG21Z

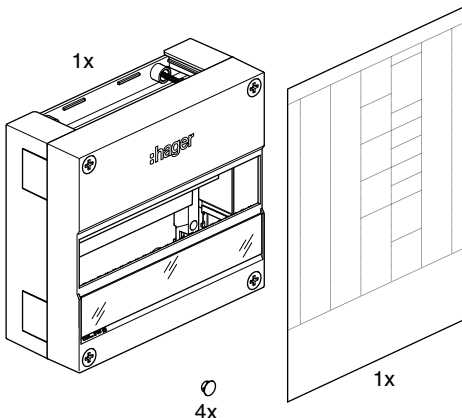

VKG22Z

